

# Dial Test Indicator Parallel Type

Item number: 513-482-10A

## Images



## Description

This is a Dial Test Indicator (Lever Type) which offers you the following benefits:

- Drastically enhanced durability, sensitivity and visibility.
- Glare-free flat crystal face allows easy reading of graduations.
- O-ring seal on the bezel has the effect of providing smooth rotation and prevents dust and oil from penetrating through to the dial face.
- The stylus length is on the dial face to reorder a replacement
- Multi-layer coatings on the crystal.


## Features

<b>Digital/Analog:</b>	Analog
<b>Inch-Metric:</b>	Inch
<b>Delivered:</b>	In a box with stem $\varnothing 3/8$ " (9,52 mm) / 0,157" (4 mm), stylus $\varnothing 0,039$ "/0,079"/0,118"
<b>Range:</b>	0,03 "
<b>Dial reading:</b>	0-15-0
<b>Graduation:</b>	0.0005"
<b>H MPE (Hysteresis):</b>	0.0002"
<b>R MPE (Repeatability):</b>	$\pm 0.0002$ "
<b>MPE first one revolution:</b>	$\pm 0.0005$ "
<b>Measuring force:</b>	0,01-0,3 N
<b>Mass:</b>	68 g
<b>Contact point:</b>	Thread M 1.7 x 0.35

Remarks:

Plus set

## Dimensions

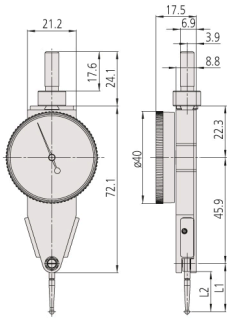

**L1:** 19.9 mm

**L2:** 16.4 mm

## Accessories

### Optional accessories:



### Limit Hands (Green) 2 pcs.

Dial Indicator Series 1, Test Indicator

Art No. 21AAB363

Price on application

### Standard accessories:



### Stem for Standard Type Series 513

D=4mm

Art No. 21CAB106

Suggested retail price: 15.00 €\*

Art No. 21CAB105

Suggested retail price: 7.04 €\*



## Knurled Clamp Ring for Stem

Lever Indicator Serie 513

Art No. 190322

Suggested retail price: 12.00 €\*  


## Point Dia 2mm/513

L=0.76"


Art No. 133195

Price on application  


## Stylus for Series 513

Ø0,04", 0,79" length, Steel

Art No. 133196

Suggested retail price: 11.00 €\*  


## Stylus for Series 513

Ã 0,12",0,79" length, Steel

Art No. 133197

Suggested retail price: 12.00 €\*  
