


Dial Test Indicator Parallel Type

Item number: 513-482-10T

Images

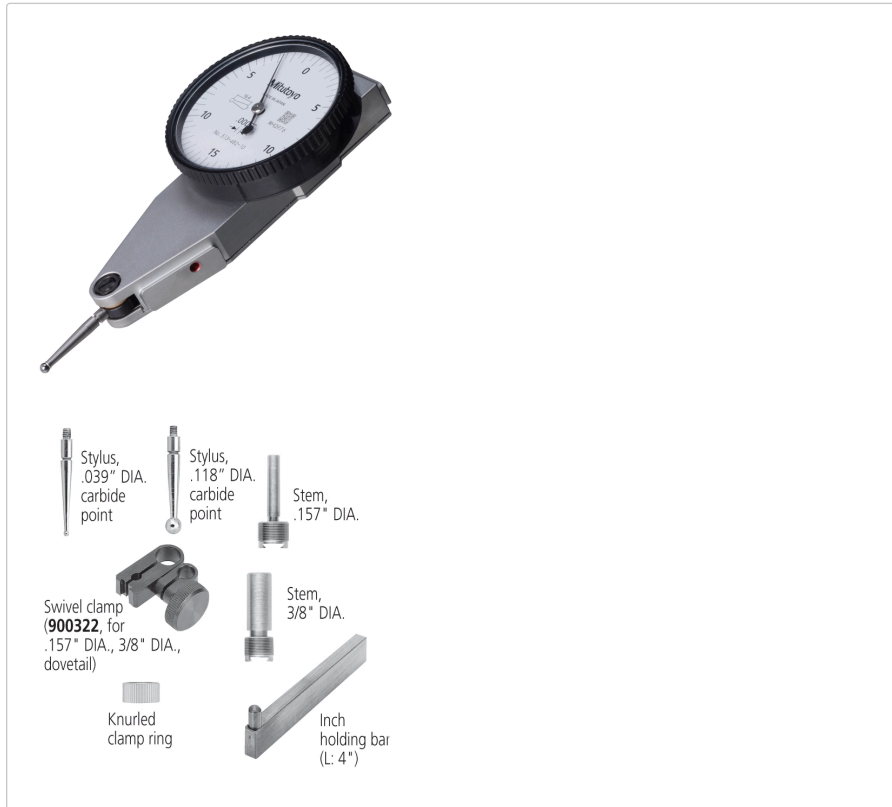


Description

A Mitutoyo versatile lever indicator (or dial test indicator, DTI) suited to alignment operations on machine tools and similar applications. This indicator automatically adapts to the required measuring direction on contact, and the jewelled movement provides lowest friction and stiction for smooth and precise operation. Supplied with a comprehensive set of mounting accessories and interchangeable styli that enable immediate use in almost any situation.

Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Delivered:	In a box with stem $\varnothing 3/8"$ (9,52 mm) / 0,157" (4 mm), stylus $\varnothing 0,039"/0,079"/0,118"$, swivel clamp / holding bar
Dial reading:	0-15-0
Graduation:	0.0005"
H MPE (Hysteresis):	0.0002"
R MPE (Repeatability):	$\pm 0.0002"$
MPE first one revolution:	$\pm 0.0005"$
Measuring force:	0,01-0,3 N
Mass:	68 g
Contact point:	Thread M 1.7 x 0.35
Remarks:	Full set

Dimensions

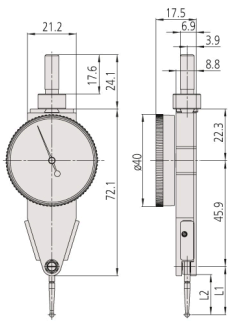

L1: 19.9 mm

L2: 16.4 mm

Accessories

Optional accessories:



Limit Hands (Green) 2 pcs.

Dial Indicator Series 1, Test Indicator
Art No. 21AAB363

Price on application

Standard accessories:



Stem for Standard Type Series 513

D=4mm

Art No. 21CAB106

Suggested retail price: 15.00 €*

Art No. 21CAB105

Suggested retail price: 7.04 €*



Knurled Clamp Ring for Stem

Lever Indicator Serie 513

Art No. 190322

Suggested retail price: 12.00 €*



Point Dia 2mm/513

L=0.76"

Art No. 133195

Price on application



Stylus for Series 513

Ø0,04", 0,79" length, Steel

Art No. 133196

Suggested retail price: 11.00 €*



Stylus for Series 513

Ã 0,12",0,79" length, Steel

Art No. 133197

Suggested retail price: 12.00 €*



Art No. 901162

Price on application



