

Vernier Height Gauge

Item number: 514-102

Images



Description


This vernier height gauge offers you the following benefits:

- You can take accurate and fast readings thanks to the satin chrome finished main and vernier scales.
- A carbide-tipped scriber is provided.

Features

Digital/Analog:	Analog
Range:	0 - 300 mm
Graduation:	0,02 mm
Delivered:	Including carbide tipped scriber, scriber clamp
Max. Permissible Error E MPE:	$\pm 0,04$ mm
Fine adjustment:	4 mm
Scale adjustment:	15 mm
Inch-Metric:	Metric
Mass:	3.1 kg

Dimensions

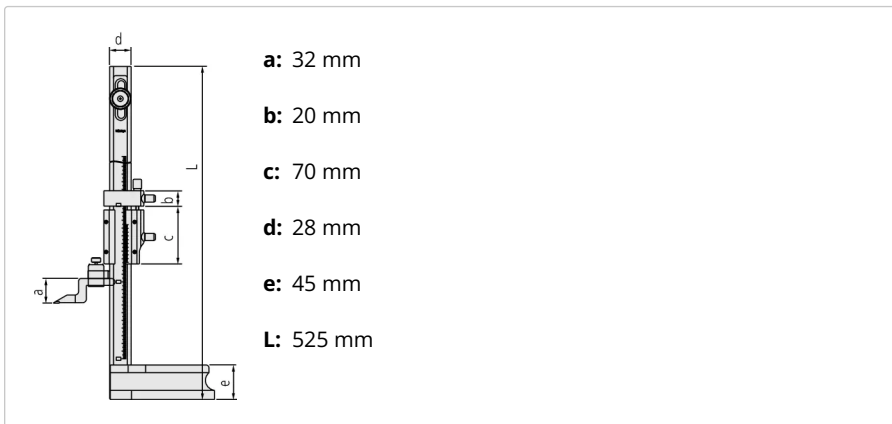

Accessories

Optional accessories:

Holding Bar for Swivel Clamp

9x9mm, 50mm Length
Art No. 953638
Suggested retail price: 24.00 €*




Holding Bar for Swivel Clamp

9x9mm, 100mm Length
Art No. 900209
Suggested retail price: 17.30 €*



Swivel Clamp

for D= 4/8mm, Dovetail
Art No. 900321
Suggested retail price: 26.50 €*

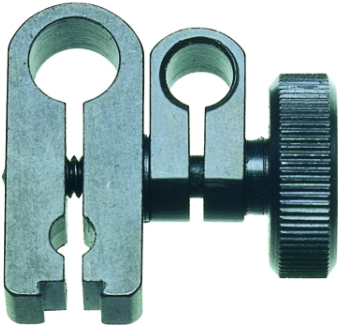

Magnifier for Vernier Height Gauge

300, 450, 600mm
Art No. 07GZA003
Suggested retail price: 43.00 €*



Center Master

for 9x9mm
Art No. 951144
Suggested retail price: 183.00 €*



Depth Gauge Attachment



for 9x9 mm
Art No. 900764
Suggested retail price: 59.00 €*
Suggested retail price: 59.00 €*

Contact Sensor



for Height Gauges
Art No. 900872
Suggested retail price: 135.00 €*
Suggested retail price: 135.00 €*

Standard accessories:



Scriber Clamp

for 9x9mm Scriber
Art No. 05GZA033
Suggested retail price: 58.00 €*
Suggested retail price: 58.00 €*



Carbide Tipped Scriber

9x9mm, 80mm Length
Art No. 07GZA000
Suggested retail price: 69.00 €*
Suggested retail price: 69.00 €*