


Vernier Height Gauge

Item number: 514-103

Images

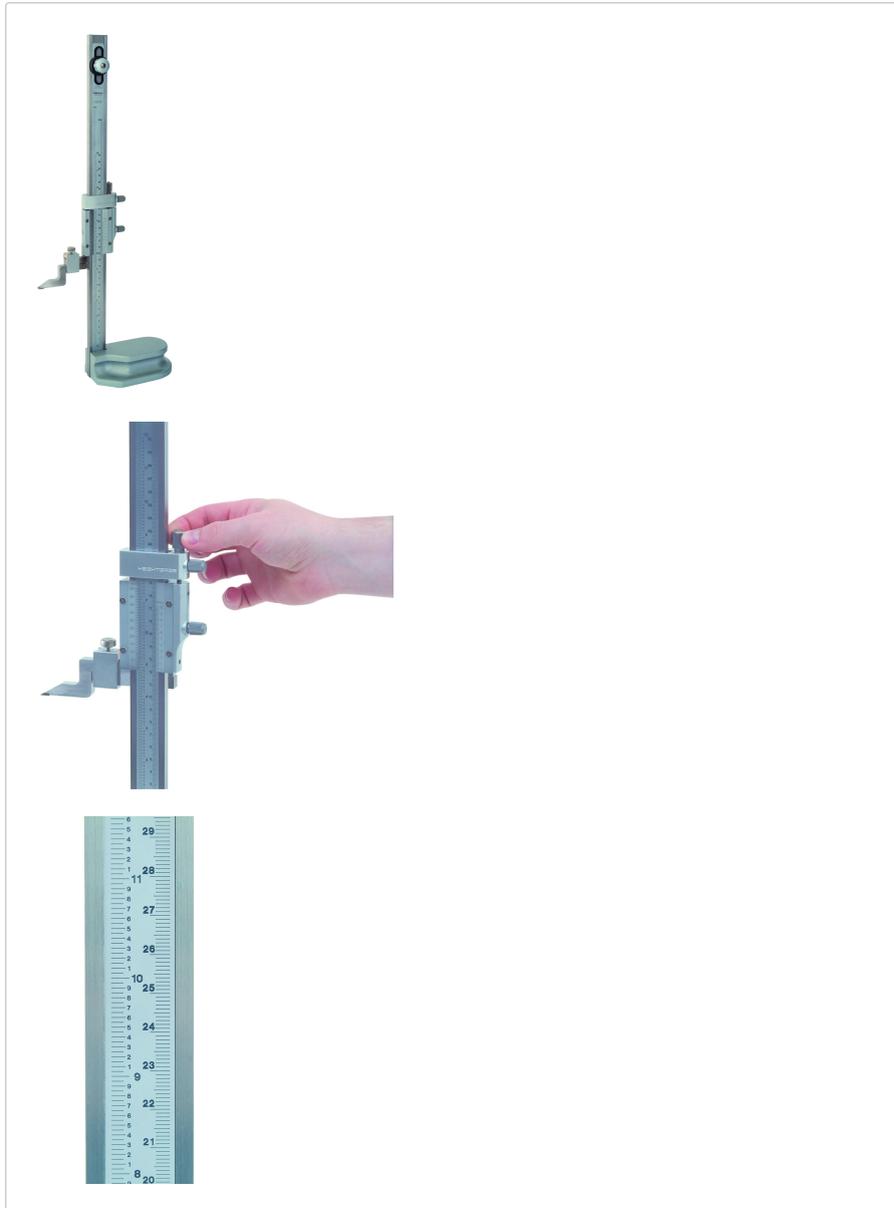

Description

A Mitutoyo vernier height gauge with a dual unit, adjustable main scale. Stainless steel construction with easy-to-read, satin-chromed scales.

Features

Digital/Analog:	Analog
Range:	0 - 12 "
Graduation:	0.001"/0.02 mm
Delivered:	Including carbide tipped scriber, scriber clamp
Max. Permissible Error E MPE:	$\pm 0,002"/\pm 0,04$ mm
Fine adjustment:	4 mm/0.16"
Max. Permissible Error J MPE:	± 0.04 mm/0.002"
Scale adjustment:	0.6"

Inch-Metric:

Inch/Metric

Mass:

3.1 kg

Accessories

Optional accessories:



Holding Bar for Swivel Clamp

9x9mm, 50mm Length

Art No. 953638

Suggested retail price: 24.00 €*




Holding Bar for Swivel Clamp

9x9mm, 100mm Length

Art No. 900209

Suggested retail price: 17.30 €*

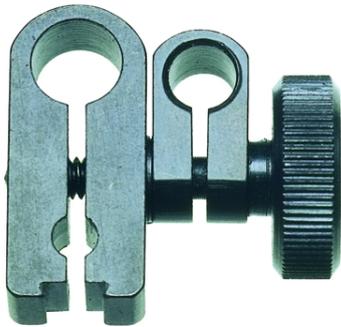

Swivel Clamp

for D= 4/8mm, Dovetail

Art No. 900321

Suggested retail price: 26.50 €*



Magnifier for Vernier Height Gauge

300, 450, 600mm

Art No. 07GZA003

Suggested retail price: 43.00 €*

Center Master

for 9x9mm
Art No. 951144
Suggested retail price: 183.00 €*



Depth Gauge Attachment

for 9x9 mm
Art No. 900764
Suggested retail price: 59.00 €*



Contact Sensor

for Height Gauges
Art No. 900872
Suggested retail price: 135.00 €*



Standard accessories:

Scriber Clamp

for 9x9mm Scriber
Art No. 05GZA033
Suggested retail price: 58.00 €*





Carbide Tipped Scriber

9x9mm, 80mm Length

Art No. 07GZA000

Suggested retail price: 69.00 €*
