

Dial Snap Meter

Item number: 523-122

Images




Description

A Mitutoyo rapid-retraction-anvil snap meter equipped with a high resolution dial indicator.

Features

Digital/Analog:	Analog
Inch-Metric:	Metric
Range:	25 - 50 mm
Graduation:	0.001 mm
Delivered:	Including box, workpiece rest, setting standard
Indicating range:	± 0.06 mm
Anvil retracting stroke:	2 mm
Accuracy dial comparator:	1 μ m
Repeatability:	0.4 μ m
Flatness:	0,3 μ m
Parallelism:	0,6 μ m
Measuring face:	Carbide-tipped, micro-lap finish $\varnothing 10.8$ mm
Measuring spindle:	$\varnothing 10,8$ mm
Measuring force:	5 - 10 N
Mass:	840 g

Dimensions

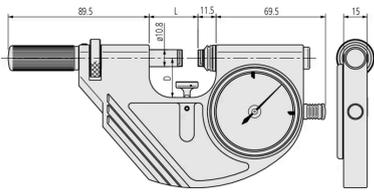

L: 56 mm

D: 35 mm

Accessories

Standard accessories:



Micrometer Setting Standard

Length: 25mm

Art No. 167-101

Suggested retail price: 33.00 €*