

## Dial Snap Meter

Item number: 523-132

### Images




### Description

A Mitutoyo rapid-retraction-anvil snap meter equipped with a high resolution dial indicator.

### Features

<b>Digital/Analog:</b>	Analog
<b>Inch-Metric:</b>	Inch
<b>Range:</b>	1 - 2 "
<b>Graduation:</b>	0.00005"
<b>Delivered:</b>	Including box, workpiece rest, setting standard
<b>Indicating range:</b>	$\pm 0.0023$ "
<b>Anvil retracting stroke:</b>	2 mm
<b>Accuracy dial comparator:</b>	1 $\mu$ m
<b>Repeatability:</b>	0.00002"
<b>Flatness:</b>	0.000012"
<b>Parallelism:</b>	0.000024"
<b>Measuring face:</b>	Carbide-tipped, micro-lap finish $\varnothing 10.8$ mm
<b>Measuring spindle:</b>	$\varnothing 10,8$ mm
<b>Measuring force:</b>	5 - 10 N
<b>Mass:</b>	840 g

### Dimensions

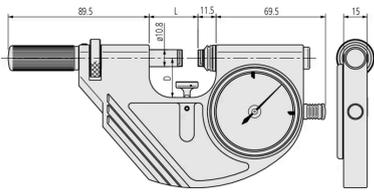

**L:** 56 mm

**D:** 35 mm

## Accessories

Standard accessories:



### Micrometer Setting Standard

Length: 1"

Art No. 167-141

Suggested retail price: 33.00 €\*