

Dial Snap Meter

Item number: 523-134

Images



Description

A Mitutoyo rapid-retraction-anvil snap meter equipped with a high resolution dial indicator.


Features

Digital/Analog:	Analog
Inch-Metric:	Inch
Range:	3 - 4 "
Graduation:	0.00005"
Delivered:	Including box, workpiece rest, setting standard
Indicating range:	± 0.0023 "
Anvil retracting stroke:	2 mm
Accuracy dial comparator:	1 μ m
Repeatability:	0.00002"
Flatness:	0.000012"
Parallelism:	0.00004"
Measuring face:	Carbide-tipped, micro-lap finish $\varnothing 10.8$ mm
Measuring spindle:	$\varnothing 10,8$ mm
Measuring force:	5 - 10 N

Mass:

1080 g

Dimensions

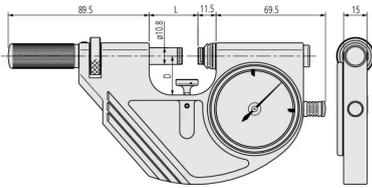

L: 106 mm

D: 60 mm

Accessories

Standard accessories:



Micrometer Setting Standard

Length: 3"

Art No. 167-143

Suggested retail price: 37.00 €*