


2-Point Inside Measuring Instrument

Item number: 526-104

Images

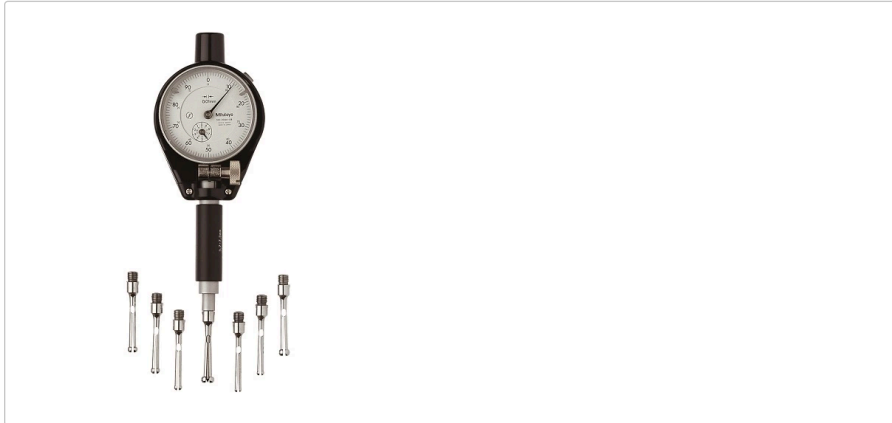

Description


This is a two point split contact point ideally suited to smaller bore measurements. It offers you the following benefits:

- A precision bore gauge so you can make quick and accurate measurements of small hole diameters (0.95-18 mm).
- You can replace the analogue indicator fitted to this instrument with a customer-supplied Digimatic indicator if you need.
- The contact point is hard chrome coated.

Features

Range:	0,4 - 0,7 "
Repeatability:	2 μ m
Number of anvils:	8
Delivered:	In a box, without dial indicator, cover for dial indicator and setting ring

Dimensions

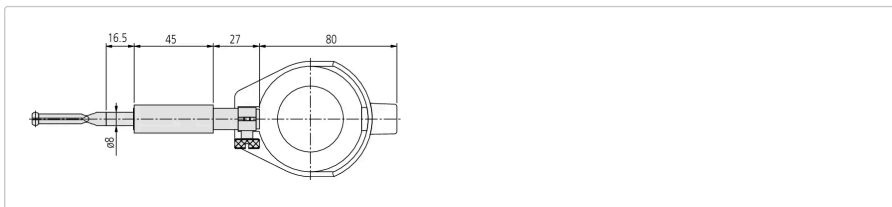

Accessories

Optional accessories:



Stand for Bore Gauge Series 526

D=60mm Table, 38mm Table Stroke
Art No. 215-120-10
Suggested retail price: 1,178.00 €*



Digital Indicator, Bore Gauge ID-C

ASME/ANSI Type, Inch/Metric, 0,5", 0,00005",
Flat Back Plate
Art No. 543-312B-10
Suggested retail price: 563.00 €*



Limit Hands (green) 2pcs

Dial Indicator Series 2/3/4
Art No. 21AZB195
Price on application

Standard accessories:



Contact Point for Serie 526

10-11mm
Art No. 102454
Suggested retail price: 66.00 €*



Contact Point for Serie 526

11-12mm
Art No. 102455
Suggested retail price: 66.00 €*



Contact Point for Serie 526

12-13mm
Art No. 102456
Suggested retail price: 66.00 €*



Contact Point for Serie 526

13-14mm
Art No. 102457
Suggested retail price: 66.00 €*



Contact Point for Serie 526

14-15mm
Art No. 102458
Suggested retail price: 66.00 €*



Contact Point for Serie 526

15-16mm
Art No. 102459
Suggested retail price: 66.00 €*



Contact Point for Serie 526

16-17mm

Art No. 102460

Suggested retail price: 66.00 €*
*



Contact Point for Serie 526

17-18mm

Art No. 102461

Suggested retail price: 66.00 €*
*



Spanner/526

Art No. 102148

Price on application