


## 2-Point Inside Measuring Instrument

Item number: 526-119-20

### Images

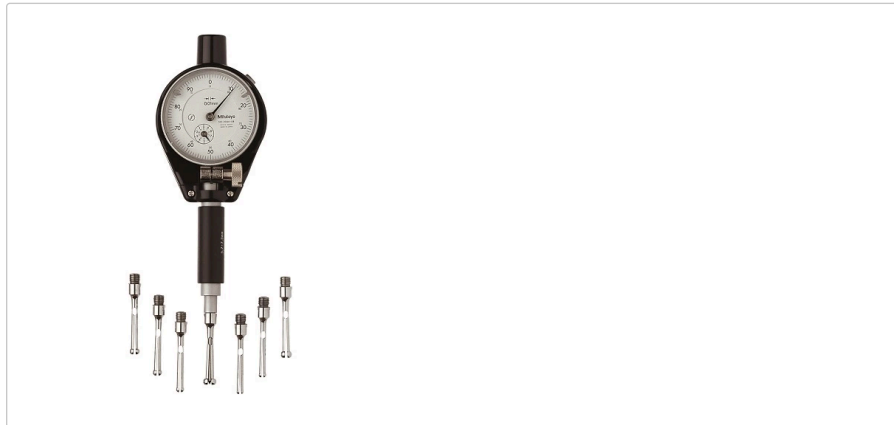

### Description


This is a two point split contact point ideally suited to smaller bore measurements. It offers you the following benefits:

- A precision bore gauge so you can make quick and accurate measurements of small hole diameters (0.95-18 mm).
- You can replace the analogue indicator fitted to this instrument with a customer-supplied Digimatic indicator if you need.
- The contact point is hard chrome coated.

### Features

<b>Inch-Metric:</b>	Inch
<b>Digital/Analog:</b>	Analog
<b>Range:</b>	0.3 - 0.4 "
<b>Graduation:</b>	0.0005"
<b>Repeatability:</b>	2 $\mu$ m
<b>Measuring depth:</b>	2.2"
<b>No. Dial Indicator:</b>	2922AB
<b>Number of anvils:</b>	6
<b>Accuracy:</b>	4 $\mu$ m 6 $\mu$ m for range 0.4-0.7 "
<b>Delivered:</b>	In a box, with dial indicator and cover for dial indicator, without setting ring

### Dimensions

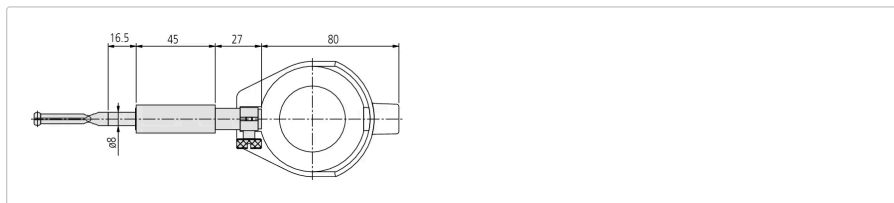

### Accessories

Optional accessories:



## Stand for Bore Gauge Series 526

D=60mm Table, 38mm Table Stroke  
Art No. 215-120-10  
Suggested retail price: 1,178.00 €\*  
\*



## Digital Indicator, Bore Gauge ID-C

ASME/ANSI Type, Inch/Metric, 0,5", 0,00005",  
Flat Back Plate  
Art No. 543-312B-10  
Suggested retail price: 563.00 €\*  
\*



## Limit Hands (green) 2pcs

Dial Indicator Series 2/3/4  
Art No. 21AZB195  
Price on application

Standard accessories:



## 2-Point Inside Measuring Instrument

Bore Gauge for Extra Small Holes, 0,3-0,4",  
w/o Indicator  
Art No. 526-103  
Suggested retail price: 293.00 €\*  
\*



**Dial Gauge, Flat Back,  
ANSI/AGD Type**

0,125", 0,0005"

Art No. 2922AB

Suggested retail price: 107.00 €\*  

---



**Protector for Indicator (plastic  
cover)**

Art No. 21DZA000

Suggested retail price: 20.00 €\*  

---