

2-Point Inside Measuring Instrument

Item number: 526-126-20

Images



Description


This is a two point split contact point ideally suited to smaller bore measurements. It offers you the following benefits:

- A precision bore gauge so you can make quick and accurate measurements of small hole diameters (0.95-18 mm).
- You can replace the analogue indicator fitted to this instrument with a customer-supplied Digimatic indicator if you need.
- The contact point is hard chrome coated.

Features

Inch-Metric:	Metric
Digital/Analog:	Analog
Range:	7 - 10 mm
Graduation:	0.01mm
Accuracy:	4 μ m
Repeatability:	2 μ m
Measuring depth:	40-56 mm ⁽²⁾
No. Dial Indicator:	2046AB
Number of anvils:	6
Delivered:	In a box, with dial indicator and cover for dial indicator, without setting ring
Mass:	300 g

Dimensions

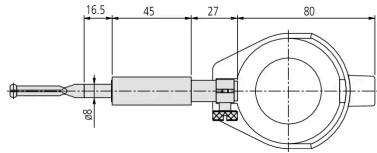

Accessories

Optional accessories:



Stand for Bore Gauge Series 526

D=60mm Table, 38mm Table Stroke
Art No. 215-120-10
Suggested retail price: 1,178.00 €*



Digital Indicator, Bore Gauge ID-C

12,7mm, 0,001mm, Flat Back Plate
Art No. 543-310B-10
Suggested retail price: 563.00 €*



Limit Hands (green) 2pcs

Dial Indicator Series 2/3/4
Art No. 21AZB195
Price on application

Standard accessories:



2-Point Inside Measuring Instrument

Bore Gauge for Extra Small Holes, 7-10mm, w/o Indicator

Art No. 526-101

Suggested retail price: 293.00 €*

Promotion!



Dial Gauge, Flat Back, ISO Type

10mm, 0,01mm

Art No. 2046AB

Promo price: **37.90 €***

Suggested retail price: 48.00 €*



Protector for Indicator (plastic cover)

Art No. 21DZA000

Suggested retail price: 20.00 €*