


2-Point Inside Measuring Instrument

Item number: 526-150-11

Images

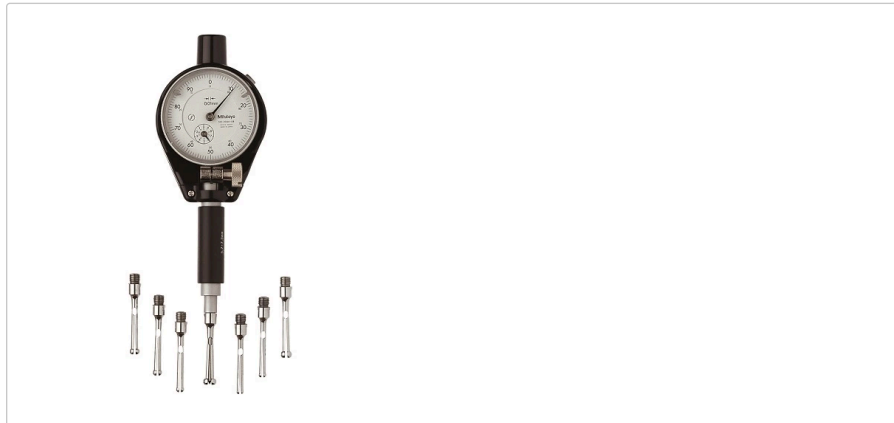

Description


This is a two point split contact point ideally suited to smaller bore measurements. It offers you the following benefits:

- A precision bore gauge so you can make quick and accurate measurements of small hole diameters (0.95-18 mm).
- You can replace the analogue indicator fitted to this instrument with a customer-supplied Digimatic indicator if you need.
- The contact point is hard chrome coated.

Features

Repeatability:	2 μ m
Delivered:	In a box, without dial indicator and cover for dial indicator, with setting ring

Dimensions

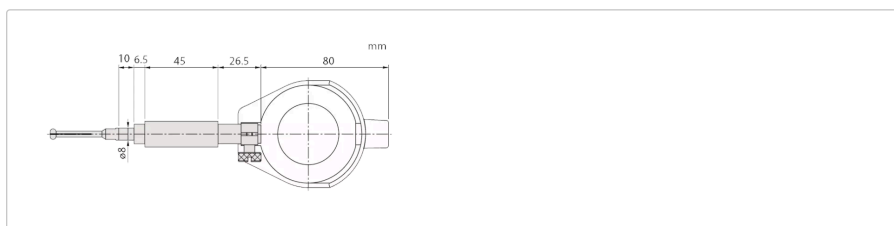

Accessories

Optional accessories:



Stand for Bore Gauge Series 526

D=60mm Table, 38mm Table Stroke

Art No. 215-120-10

Suggested retail price: 1,178.00 €*



Digital Indicator, Bore Gauge ID-C

12,7mm, 0,001mm, Flat Back Plate
Art No. 543-310B-10
Suggested retail price: 563.00 €*



Limit Hands (green) 2pcs

Dial Indicator Series 2/3/4
Art No. 21AZB195
Price on application

Standard accessories:



Setting Ring 4mm

Steel
Art No. 177-204
Suggested retail price: 126.00 €*



Setting Ring 4,5mm

Steel
Art No. 177-257
Suggested retail price: 126.00 €*

Setting Ring 5mm



Steel

Art No. 177-205

Suggested retail price: 126.00 €*

Setting Ring 5,5mm



Steel

Art No. 177-263

Suggested retail price: 126.00 €*

Setting Ring 6mm



Steel

Art No. 177-267

Suggested retail price: 126.00 €*

Setting Ring 6,5mm



Steel

Art No. 177-271

Suggested retail price: 126.00 €*

Setting Ring 7,0mm



Steel

Art No. 177-275

Suggested retail price: 126.00 €*
