


2-Point Inside Measuring Instrument

Item number: 526-160-11

Images

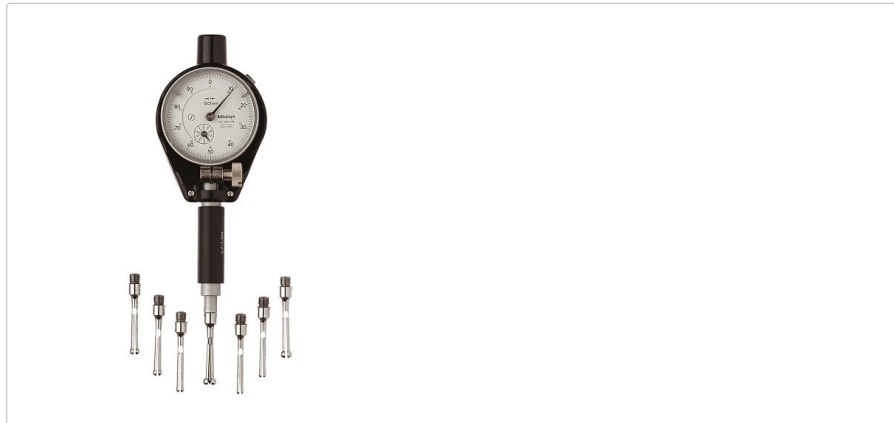

Description


This is a two point split contact point ideally suited to smaller bore measurements. It offers you the following benefits:

- A precision bore gauge so you can make quick and accurate measurements of small hole diameters (0.95-18 mm).
- You can replace the analogue indicator fitted to this instrument with a customer-supplied Digimatic indicator if you need.
- The contact point is hard chrome coated.

Features

Repeatability:	2 μ m
Delivered:	In a box, without dial indicator and cover for dial indicator, with setting ring

Dimensions

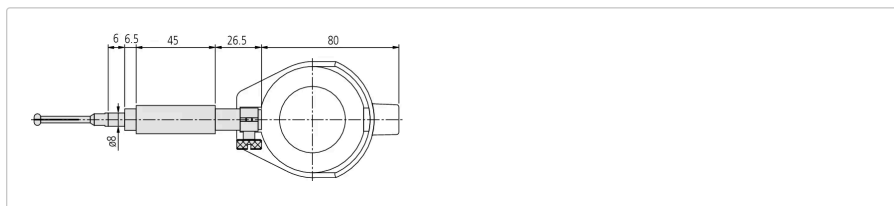

Accessories

Optional accessories:



Stand for Bore Gauge Series 526

D=60mm Table, 38mm Table Stroke
Art No. 215-120-10
Suggested retail price: 1,178.00 €*



Digital Indicator, Bore Gauge ID-C

12,7mm, 0,001mm, Flat Back Plate
Art No. 543-310B-10
Suggested retail price: 563.00 €*



Limit Hands (green) 2pcs

Dial Indicator Series 2/3/4
Art No. 21AZB195
Price on application

Standard accessories:



Setting Ring 1,75mm

Steel
Art No. 177-236
Suggested retail price: 126.00 €*



Setting Ring 2,0mm

Steel
Art No. 177-239
Suggested retail price: 126.00 €*

Setting Ring 2,25mm



Steel

Art No. 177-242

Suggested retail price: 126.00 €*

Setting Ring 2,5mm



Steel

Art No. 177-208

Suggested retail price: 126.00 €*

Setting Ring 2,75mm



Steel

Art No. 177-246

Suggested retail price: 126.00 €*

Setting Ring 3,0mm



Steel

Art No. 177-248

Suggested retail price: 126.00 €*

Setting Ring 3,25mm



Steel

Art No. 177-250

Suggested retail price: 126.00 €*

Setting Ring 3,5mm

Steel

Art No. 177-252

Suggested retail price: 126.00 €*



Setting Ring 3,75mm

Steel

Art No. 177-255

Suggested retail price: 126.00 €*

