


## 2-Point Inside Measuring Instrument

Item number: 526-165-11

### Images

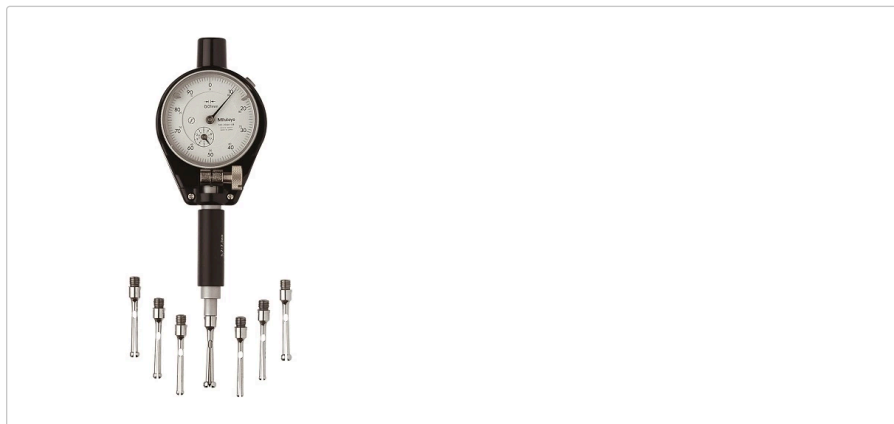

### Description


This is a two point split contact point ideally suited to smaller bore measurements. It offers you the following benefits:

- A precision bore gauge so you can make quick and accurate measurements of small hole diameters (0.95-18 mm).
- You can replace the analogue indicator fitted to this instrument with a customer-supplied Digimatic indicator if you need.
- The contact point is hard chrome coated.

### Features

<b>Repeatability:</b>	2 $\mu$ m
<b>Delivered:</b>	In a box, without dial indicator and cover for dial indicator, with setting ring

### Dimensions

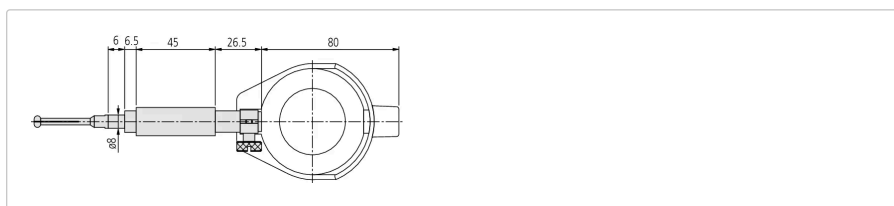

### Accessories

Optional accessories:



### Stand for Bore Gauge Series 526

D=60mm Table, 38mm Table Stroke  
Art No. 215-120-10  
Suggested retail price: 1,178.00 €\*



## Digital Indicator, Bore Gauge ID-C

ASME/ANSI Type, Inch/Metric, 0,5", 0,00005",  
Flat Back Plate  
Art No. 543-312B-10  
Suggested retail price: 563.00 €\*



## Limit Hands (green) 2pcs

Dial Indicator Series 2/3/4  
Art No. 21AZB195  
Price on application

### Standard accessories:



## Setting Ring 0.07"

Steel  
Art No. 177-355  
Suggested retail price: 126.00 €\*



## Setting Ring 0.08"

Steel  
Art No. 177-356  
Suggested retail price: 126.00 €\*



### Setting Ring 0,09"

Steel

Art No. 177-357

Suggested retail price: 126.00 €\*  

---



### Setting Ring 0,11"

Steel

Art No. 177-359

Suggested retail price: 126.00 €\*  

---



### Setting Ring 0,12"

Steel

Art No. 177-360

Suggested retail price: 126.00 €\*  

---



### Setting Ring 0,13"

Steel

Art No. 177-361

Suggested retail price: 126.00 €\*  

---



### Setting Ring 0,14"

Steel

Art No. 177-362

Suggested retail price: 126.00 €\*  

---

## Setting Ring 0,15"

Steel

Art No. 177-363

Suggested retail price: 126.00 €\*  

---

