

2-Point Inside Measuring Instrument

Item number: 526-173-21

Images



Description

This is a two point split contact point ideally suited to smaller bore measurements.


It offers you the following benefits:

- A precision bore gauge so you can make quick and accurate measurements of small hole diameters (0.95-18 mm).
- You can replace the analogue indicator fitted to this instrument with a customer-supplied Digimatic indicator if you need.
- The contact point is hard chrome coated.

Features

Inch-Metric:	Metric
Digital/Analog:	Analog
Range:	0.95 - 1.55 mm
Graduation:	0.01mm
Repeatability:	2 μ m
Measuring depth:	11.5 mm
No. Dial Indicator:	2046AB
Number of anvils:	5
Accuracy:	4 μ m 6 μ m for range 10-18 mm
Delivered:	In a box, with dial indicator, cover for dial indicator and setting ring

Dimensions

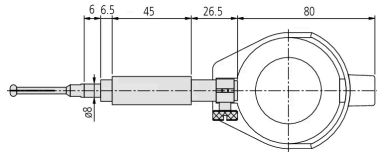

Accessories

Optional accessories:



Stand for Bore Gauge Series 526

D=60mm Table, 38mm Table Stroke
Art No. 215-120-10
Suggested retail price: 1,178.00 €*



Digital Indicator, Bore Gauge ID-C

12,7mm, 0,001mm, Flat Back Plate
Art No. 543-310B-10
Suggested retail price: 563.00 €*



Limit Hands (green) 2pcs

Dial Indicator Series 2/3/4
Art No. 21AZB195
Price on application

Standard accessories:

Promotion!



Dial Gauge, Flat Back, ISO Type

10mm, 0,01mm

Art No. 2046AB

Promo price: **37.90 €***

Suggested retail price: ~~48.00 €*~~



Protector for Indicator (plastic cover)

Art No. 21DZA000

Suggested retail price: 20.00 €*



Setting Ring 1,0mm

Steel

Art No. 177-220

Suggested retail price: 126.00 €*



Setting Ring 1,1mm

Steel

Art No. 177-222

Suggested retail price: 126.00 €*



Setting Ring 1,2mm

Steel

Art No. 177-225

Suggested retail price: 126.00 €*

Setting Ring 1,3mm

Steel

Art No. 177-227

Suggested retail price: 126.00 €*



Setting Ring 1,4mm

Steel

Art No. 177-230

Suggested retail price: 126.00 €*

