

Vernier Caliper, Standard Jaws Nib Style

Item number: 533-506

Images



Description


These vernier calipers with nib style and standard jaws let you take easy, metric measurements. They offer you the following benefits:

- You can read inside and outside measurements directly from the upper and lower vernier scales.
- Main scale and vernier scale satin chrome finish gives you high readability.

Features

Delivered:	In a box
Range:	0 - 1,000 mm
Graduation:	0.02 mm
Inside measuring from:	20.1 mm
Max. Permissible Error E MPE:	$\pm 0,07$ mm
Max. Permissible Error S MPE:	$\pm 0,07$ mm
Mass:	3450 g

Dimensions

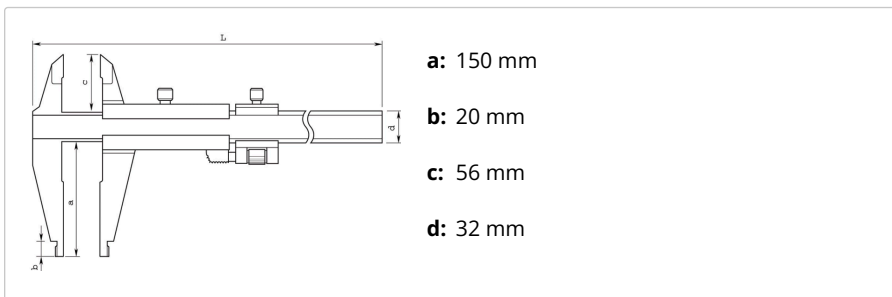

a: 150 mm

b: 20 mm

c: 56 mm

d: 32 mm