


## Linear Scale AT111

Item number: 539-215-40

### Images

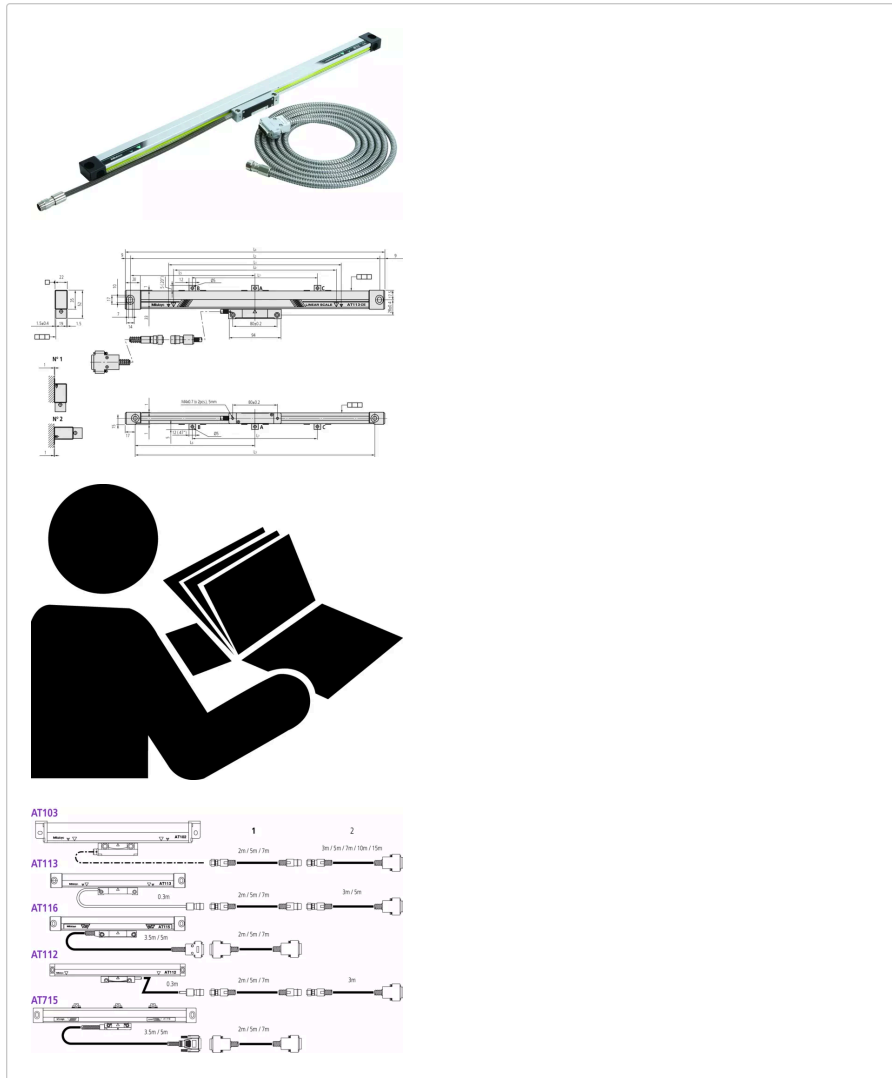

### Description

These linear scales are built for limited installation space

- Glass scale - Zero not coded
- Expansion factor  $(8 \pm 1) \times 10^{-6}/K^{-1}$
- An armoured inox signal cable is used to connect the DRO counter

### Features

<b>Model:</b>	AT113-800F
<b>Accuracy:</b>	High-accuracy type (3+3L/1000) $\mu\text{m}$ L = Effective range (mm)
<b>Output waveform:</b>	Two 90° phase-shifted sinusoidal signals
<b>Max. drive speed:</b>	120 m/min
<b>Signal period:</b>	20 $\mu\text{m}$
<b>Scale reference points:</b>	50 mm
<b>Dust/water protection level:</b>	IP53
<b>Cable length:</b>	3.5 m
<b>Effective Length:</b>	800 mm

Mass:

1.4 kg

## Accessories

### Optional accessories:



#### Extension Cable 2M

Art No. 09AAA033A

Suggested retail price: 242.00 €\*  
\*Tax included



#### Extension Cable 5M

Art No. 09AAA033B

Suggested retail price: 333.00 €\*  
\*Tax included



#### Extension Cable 7M

Art No. 09AAA033C

Suggested retail price: 384.00 €\*  
\*Tax included



#### Linear Scale Counter KA-212

Art No. 174-183D

Suggested retail price: 650.00 €\*  
\*Tax included



## Linear Scale Counter KA-213

Art No. 174-185D

Suggested retail price: 782.00 €\*  

---