


Linear Scale AT715-900

Item number: 539-816N

Images

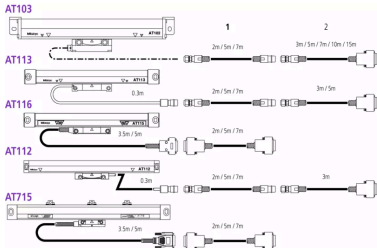

Description


This linear scale is based on electro magnetic induction principle thus offering you high environment protection IP level, in the mean time reference point is not necessary after each power on.

Only compatible with KA series display units.

Features

Model:	AT715-900
Measuring method:	Electromagnetic induction system
Accuracy:	100 to 500 mm $\pm 5 \mu\text{m}$; 600 to 1800 mm $\pm 7 \mu\text{m}$; 2000 to 3000 mm $\pm 10 \mu\text{m}$
Max. drive speed:	50 m/min
Signal period:	20 μm
Resolution:	0,001 / 0,005 (switchable via Counter)
Cable length:	3.5 m
Effective Length:	900 mm
Mass:	1.5 kg

Dimensions

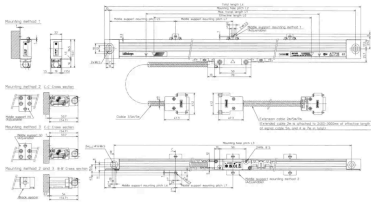

L⁰: 900 mm

L¹: 940 mm

L²: 1078 mm

L³: 1062 mm

L⁴: 1098 mm

L⁵: 539 mm

L⁶: 531 mm

Accessories

Optional accessories:



Linear Scale Counter KA-212

Art No. 174-183D

Suggested retail price: 650.00 €*

Extension Cable 2m

for AT715

Art No. 09AAB674A

Suggested retail price: 211.00 €*



Extension Cable 5m

for AT715

Art No. 09AAB674B

Suggested retail price: 297.00 €*



Extension Cable 7m

for AT715

Art No. 09AAB674C

Suggested retail price: 361.00 €*



Linear Scale Counter KA-213

Art No. 174-185D

Suggested retail price: 782.00 €*
