

## Digital Indicator ID-C

Item number: 543-700B

**Images**



- Power switch
- Data output (when connected to an external device)
- Data hold (when no external device is connected)
- Parameter setting mode: Count direction switching, tolerance judgment setting, resolution switching, scale factor setting, and function lock setting
- inch/mm conversion (inch/mm type)
- Switches between the ABS (preset) and INC (zeroset) measurement modes



Notification icon



## Description

This is a multifunction standard indicator that is reliable and easy to use.

- Bidirectional communication e.g. to perform parameter setting from a PC (Digimatic S 1 interface) is possible.
- The ABSOLUTE sensor means you don't have to carry out origin setting every time you power it on, saving you time and hassle.
- Excellent visibility with a large digital/analog display.
- Model with 0,5  $\mu\text{m}$  digital step is available.
- Measurements such as simple calculation and peak detection are possible.
- Equipped with a calibration schedule warning function.
- GO/ $\pm$ NG judgement is performed by setting the upper and lower tolerances.
- Display 330° rotatable.
- A function lock protects the display against unauthorised use.


**Features**

<b>Model:</b>	ID-C0512NXB
<b>Digital/Analog:</b>	Digital
<b>Inch-Metric:</b>	Metric
<b>Range:</b>	12.7 mm
<b>Digital step:</b>	0.0005 mm/0.001 mm/0.01mm
<b>Delivered:</b>	Including CR2032 battery, battery lid opener, certificate of inspection
<b>Max. Permissible Error E MPE (Total Range):</b>	0.003 mm
<b>H MPE (Hysteresis):</b>	0.002 mm
<b>R MPE (Repeatability):</b>	0.002 mm
<b>Measuring force MPL:</b>	≤1.5 N
<b>Protection:</b>	IP42
<b>Type:</b>	EN ISO Standard
<b>Data output:</b>	Yes
<b>Display:</b>	LCD, character height 11 mm, 330° rotatable
<b>Max. response speed:</b>	Unlimited
<b>Measurement frequency (MAX/MIN/RANGE):</b>	50 times/s
<b>Alarm:</b>	Low voltage, setting errors, sensor error, display overflow a.s.o.
<b>Stem <math>\varnothing</math>:</b>	8 mm
<b>Contact point:</b>	Carbide ball, thread: M2.5x0.45
<b>Power supply:</b>	1 battery CR2032
<b>Battery life:</b>	Approx. 2700 hours (continuous use)
<b>Digital Scale:</b>	Electrostatic capacitance type absolute linear encoder
<b>ON/OFF:</b>	Yes
<b>ABS / INC (INC ZERO):</b>	Yes
<b>Function lock:</b>	Yes
<b>GO/±NG judgement:</b>	Yes
<b>DATA/HOLD:</b>	Yes
<b>Auto Power OFF setting:</b>	Yes
<b>Counting direction switchable:</b>	Yes
<b>Customizing keys:</b>	Yes
<b>Calibration warning function:</b>	Yes
<b>Low voltage alarm:</b>	Yes
<b>Digital step switchable:</b>	Yes
<b>Digimatic S1 Bidirectional interface:</b>	Yes
<b>Analog bar resolution switchable:</b>	Yes

Inch/Metric switchable: No

Mass: 165 g

## Dimensions

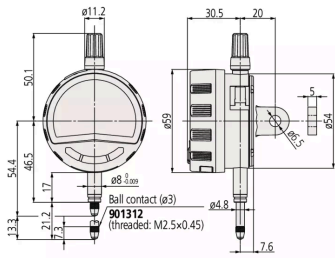

## Accessories

### Optional accessories:

Promotion!

Mitutoyo

MiCAT

the standard in world  
metrology software  
MeasurLink

### USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available  
Online)

Art No. 06AGR543

Promo price: **268.00 €\***

Suggested retail price: ~~340.00 €\*~~

USB-ITPAK



### Air Drive Unit, Indicator/Linear Gauge

for ID-S, ID-C, LGS, 12,7 mm and 0,5" Range

Art No. 903594

Suggested retail price: **189.00 €\***



### Digimatic Cable, Straight, 1m

Digimatic/Digimatic 2/Digimatic S1 Interface,  
1 m

Art No. 06AGL011

Suggested retail price: **79.00 €\***



### Digimatic Cable, Straight, 2m

Digimatic/Digimatic 2/Digimatic S1 Interface,  
2 m

Art No. 06AGL021

Suggested retail price: **84.00 €\***

Promotion!



### USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2/Digimatic  
S1 Interface

Art No. 06AGQ001F

Promo price: **129.00 €\***

Suggested retail price: ~~164.00 €\*~~

Promotion!



### USB Input Tool Interface Box

Digimatic/Digimatic 2/Digimatic S1 Interface

Art No. 264-020

Promo price: **204.00 €\***

Suggested retail price: ~~259.00 €\*~~

Promotion!



### U-WAVE fit, Buzzer Type

Wireless Transmitter for

Micrometer/Indicator

Art No. 264-623

Promo price: **129.00 €\***

Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit, IP67 Type

Wireless Transmitter for

Micrometer/Indicator

Art No. 264-622

Promo price: **129.00 €\***

Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for  
Micrometer/Indicator  
Art No. 264-627

Promo price: **129.00 €\***   
Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for  
Micrometer/Indicator  
Art No. 264-626

Promo price: **129.00 €\***   
Suggested retail price: ~~185.00 €\*~~

Promotion!



### Connection Unit for ID-C Indicator

12,7mm/0,5" Type, U-WAVE fit, U-WAVE fit  
Bluetooth for Digimatic S1 Interface  
Art No. 02AZF700

Promo price: **86.00 €\***   
Suggested retail price: ~~124.00 €\*~~

Promotion!



### Connection Cable SF for U-WAVE

for U-WAVE-T and Instruments with  
Digimatic S1 Interface  
Art No. 02AZG011

Promo price: **86.00 €\***   
Suggested retail price: ~~131.00 €\*~~



### U-WAVE fit Transmitter Mounting Plate

for ID-C, ID-S and ID-F Digital Indicator  
Art No. 02AZF670  
Suggested retail price: 47.00 €\*



### Spindle Lifting Lever

for Digital Indicator, A-Type Dial Indicator  
Serie 2/3/4

Art No. 21EZA198

Price on application



### Spindle Lifting Cable

for Indicator, L=500mm

Art No. 21JZA295

Price on application



### Spindle Lifting Cable with Auto Stop

for Indicator, L=300mm

Art No. 21JZA301

Price on application



### Spindle Lifting Knob

for 12,7mm Range

Art No. 21EZA105

Suggested retail price: 37.00 €\*

Standard accessories:



### Battery Case Opener

Art No. 21EAB049

Suggested retail price: 2.80 €\*

## Spare parts

### Consumable spares:

---



### Lithium battery CR-2032

1 pcs.

Art No. 05SAA217D

Suggested retail price: 10.00 €\*  

---