

ABS Digital Thickness Gauge with ID-S

Item number: 547-500S

Images



Description

This ABSOLUTE Digimatic Thickness Gauge is equipped with the standard and cost effective model of a digital indicator.


It enables you to measure film, paper, etc. with flat contact points and tube wall thickness.

- Monodirectional communication via Digimatic data output.

Features

Digital/Analog:	Digital
Inch-Metric:	Inch/Metric
Range:	0~0.47 " / 0~12 mm
Type:	With digital indicator with 3/8" stem refer to ANSI/AGD
Digital step:	0.0005"/0.01 mm
Delivered:	In a box with SR44 battery, spindle lifting lever 21AZB149
Parallelism:	0.0005"
Indicator No.:	ID-S No. 543-783BS (ANSI/AGD type)
Max. measuring depth:	30 mm
Max. response speed:	Unlimited
Alarm:	Low voltage, counting value composition error, overflow error
Contact point:	Thread # 4-48UNF
Power supply:	1 battery SR-44
Battery life:	Approx. 7000 hours
ON/OFF:	Yes
Inch/Metric switchable:	Yes
Mass:	225 g

Dimensions

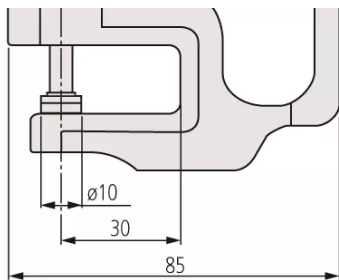

Accessories

Optional accessories:



Digimatic Cable, Flat Straight Type

1 m
 Art No. 905338
 Suggested retail price: 37.00 €*



Digimatic Cable, Flat Straight Type

2 m
 Art No. 905409
 Suggested retail price: 44.00 €*

Promotion!

USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Flat Straight Type
 Art No. 06AFM380F
Promo price: 98.00 €*
 Suggested retail price: 124.00 €*

Promotion!

U-WAVE fit, Buzzer Type

Wireless Transmitter for Micrometer/Indicator
 Art No. 264-623
Promo price: 129.00 €*
 Suggested retail price: 185.00 €*

Promotion!



U-WAVE fit, IP67 Type

Wireless Transmitter for

Micrometer/Indicator

Art No. 264-622

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for

Micrometer/Indicator

Art No. 264-627

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for

Micrometer/Indicator

Art No. 264-626

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~



U-WAVE fit Transmitter Mounting Plate

for ID-C, ID-S and ID-F Digital Indicator

Art No. 02AZF670

Suggested retail price: **47.00 €***

Promotion!



Connection Cable F for U-WAVE

Straight, without Data Button

Art No. 02AZD790F

Promo price: **68.00 €***

Suggested retail price: ~~98.00 €*~~

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: **7.00 €***