

## ABS Digital Thickness Gauge with ID-S

Item number: 547-561S

### Images



### Description

This ABSOLUTE Digimatic Thickness Gauge is equipped with the standard and cost effective model of a digital indicator.


It enables you to measure film, paper, etc. with flat contact points and tube wall thickness.

- Monodirectional communication via Digimatic data output.

### Features

|                                |   |
|--------------------------------|---|
| <b>Digital/Analog:</b>         | Digital   |
| <b>Inch-Metric:</b>            | Inch/Metric   |
| <b>Range:</b>                  | 0~0.47 " / 0~12 mm  |
| <b>Type:</b>                   | With digital indicator with 3/8" stem refer to ANSI/AGD       |
| <b>Digital step:</b>           | 0.0005"/0.01 mm   |
| <b>Delivered:</b>              | In a box with SR44 battery, spindle lifting lever 21AZB149    |
| <b>Indicator No.:</b>          | ID-S No. 543-783BS (ANSI/AGD type)                            |
| <b>Data output:</b>            | Yes   |
| <b>Max. response speed:</b>    | Unlimited   |
| <b>Alarm:</b>                  | Low voltage, counting value composition error, overflow error |
| <b>Contact point:</b>          | Thread # 4-48UNF  |
| <b>Power supply:</b>           | 1 battery SR-44   |
| <b>Battery life:</b>           | Approx. 7000 hours  |
| <b>ON/OFF:</b>                 | Yes   |
| <b>Inch/Metric switchable:</b> | Yes   |
| <b>Mass:</b>                   | 215 g   |

### Dimensions

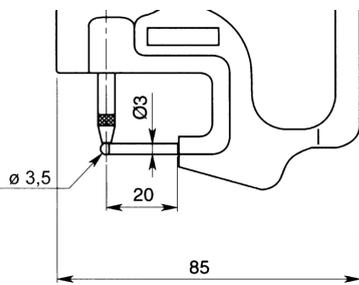

## Accessories

Optional accessories:

Promotion!

Mitutoyo

MiCAT  
the standard in world  
metrology software  
MeasurLink

### USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Promo price: **268.00 €\***

Suggested retail price: ~~340.00 €\*~~

USB-ITPAK



### Digimatic Cable, Flat Straight Type

1 m

Art No. 905338

Suggested retail price: 37.00 €\*



### Digimatic Cable, Flat Straight Type

2 m

Art No. 905409

Suggested retail price: 44.00 €\*

Promotion!



### USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Flat Straight Type

Art No. 06AFM380F

Promo price: **98.00 €\***

Suggested retail price: ~~124.00 €\*~~

Promotion!



### U-WAVE fit, Buzzer Type

Wireless Transmitter for  
Micrometer/Indicator  
Art No. 264-623

Promo price: **129.00 €\***  
Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit, IP67 Type

Wireless Transmitter for  
Micrometer/Indicator  
Art No. 264-622

Promo price: **129.00 €\***  
Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for  
Micrometer/Indicator  
Art No. 264-627

Promo price: **129.00 €\***  
Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for  
Micrometer/Indicator  
Art No. 264-626

Promo price: **129.00 €\***  
Suggested retail price: ~~185.00 €\*~~



### U-WAVE fit Transmitter Mounting Plate

for ID-C, ID-S and ID-F Digital Indicator  
Art No. 02AZF670  
Suggested retail price: **47.00 €\***

Promotion!



## Connection Cable F for U-WAVE

Straight, without Data Button

Art No. 02AZD790F

Promo price: **68.00 €\***

Suggested retail price: ~~98.00 €\*~~

### Spare parts

Consumable spares:



## Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €\*