
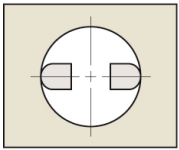


## Digital ABS Caliper, Nib Style Jaws IP67

Item number: 550-341-20

### Images

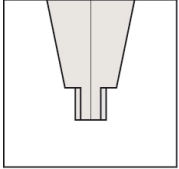

Dust- and  
Water-  
Protected

www.tuv.com  
ID 0000045042

# ABSOLUTE®

### Description

This is a Digimatic caliper with nib-style jaws that lets you measure inside dimensions. It offers you the following benefits:


- Rounded measuring surfaces enable you to measure inside dimensions.
- ABSOLUTE System delivers reliable measurements.

### Features

<b>Model:</b>	CDC-P12"
<b>Delivered:</b>	In a box with SR44 battery
<b>Digital/Analog:</b>	Digital
<b>Inch-Metric:</b>	Inch/Metric
<b>Range:</b>	0 - 12 "
<b>Inside measuring from:</b>	0.404"/10.26 mm

<b>Max. Permissible Error E MPE:</b>	±0.002"
<b>Max. Permissible Error S MPE:</b>	±0.002"
<b>OFFSET:</b>	0.4"
<b>Mass:</b>	365 g
<b>Digital step:</b>	0.0005"/0.01 mm
<b>Max. response speed:</b>	Unlimited
<b>Display:</b>	LCD, character height 9 mm (200 mm) 11 mm (300 mm) 10 mm (>300 mm)
<b>Remarks:</b>	IP67
<b>Battery life:</b>	Approx. 5 years, 3,5 years (>300 mm)
<b>ORIGIN (ABS-Zero):</b>	Yes
<b>PRESET:</b>	Yes
<b>Auto Power OFF after 20 min. non use:</b>	Yes
<b>Low voltage alarm:</b>	Yes
<b>Data output:</b>	Yes

## Dimensions

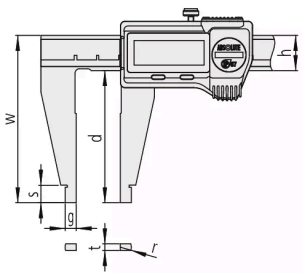



<b>d:</b>	75 mm
<b>g:</b>	5.08 mm
<b>s:</b>	12 mm
<b>w:</b>	95 mm
<b>h:</b>	20 mm
<b>t:</b>	3.8 mm
<b>R:</b>	5.08 mm


## Accessories

Optional accessories:

Promotion!

the standard in world metrology software




### USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

**Promo price: 259.00 €\***

Suggested retail price: ~~340.00 €\*~~





### Digimatic Cable with Data Button IP Type

1m, Caliper Type  
Art No. 05CZA624  
Suggested retail price: 100.00 €\*  

---



### Digimatic Cable with Data Button IP Type

2m, Caliper Type  
Art No. 05CZA625  
Suggested retail price: 107.00 €\*  

---

Promotion!



### USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Caliper Type  
Art No. 06AFM380A  
Promo price: **109.00 €\***   
Suggested retail price: ~~141.00 €\*~~

Promotion!



### U-WAVE fit, IP67 Type

Wireless Transmitter for Caliper  
Art No. 264-620  
Promo price: **129.00 €\***   
Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit, Buzzer Type

Wireless Transmitter for Caliper  
Art No. 264-621  
Promo price: **129.00 €\***   
Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for Caliper  
Art No. 264-624

Promo price: **139.00 €\***   
Suggested retail price: ~~185.00 €\*~~

Promotion!



### U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for Caliper  
Art No. 264-625

Promo price: **139.00 €\***   
Suggested retail price: ~~185.00 €\*~~

Promotion!



### Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit Bluetooth  
Art No. 02AZF310

Promo price: **74.90 €\***   
Suggested retail price: ~~110.00 €\*~~

## Spare parts

Consumable spares:



### Battery SR44 1,5 V

Art No. 938882  
Suggested retail price: 10.00 €\*