
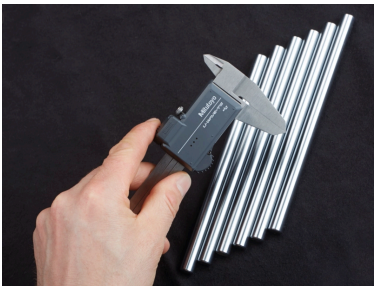
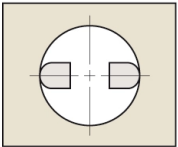
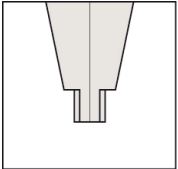


Digital ABS Caliper Nib Style/Std. Jaws

Item number: 551-311-20

Images

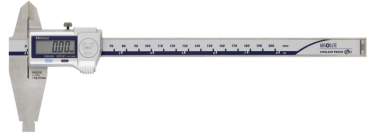

ABSOLUTE®

IP67



Dust- and
Water-
Protected

www.tuv.com
ID 0000045042

Description

This is a Digimatic caliper with nib-style and standard jaws.


It offers you the following benefits:

- Knife-shaped measuring surfaces allow you to take outside measurements.
- Rounded measuring surfaces enable you to measure inside dimensions.
- ABSOLUTE System delivers reliable measurements.

Features

Delivered:	In a box with SR44 battery
Digital/Analog:	Digital
Inch-Metric:	Inch/Metric
Range:	0 - 8 "
Inside measuring from:	0.404"/10.26 mm
Max. Permissible Error E MPE:	±0.0015"
Max. Permissible Error S MPE:	±0.0015"
OFFSET:	0.4"
Mass:	190 g
Digital step:	0.0005"/0.01 mm
Max. response speed:	Unlimited
Display:	LCD, character height 9 mm (200 mm) 11 mm (300 mm) 10 mm (>300 mm)
Remarks:	IP67
Battery life:	Approx. 5 years, 3,5 years (>300 mm)
ORIGIN (ABS-Zero):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Data output:	Yes

Dimensions

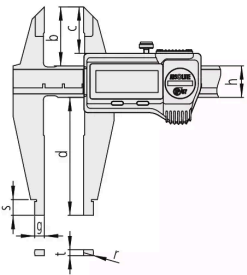

b: 30 mm

c: 23.6 mm

d: 60 mm

g: 5.08 mm

s: 8 mm

h: 16 mm

t: 3 mm

R: 5.08 mm

Accessories

Optional accessories:

Promotion!

Mitutoyo

MiCAT

the standard in world
metrology software
MeasurLink®

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)

Art No. 06AGR543

Promo price: **259.00 €***

Suggested retail price: ~~340.00 €*~~

A red rectangular box with the text "USB-ITPAK" in white.

Digimatic Cable with Data Button IP Type

2m, Caliper Type

Art No. 05CZA625

Suggested retail price: 107.00 €*



Digimatic Cable with Data Button IP Type

1m, Caliper Type

Art No. 05CZA624

Suggested retail price: 100.00 €*

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data
Button IP Caliper Type

Art No. 06AFM380A

Promo price: **109.00 €***

Suggested retail price: ~~141.00 €*~~

Promotion!



U-WAVE fit, IP67 Type

Wireless Transmitter for Caliper

Art No. 264-620

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit, Buzzer Type

Wireless Transmitter for Caliper
Art No. 264-621

Promo price: **129.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for Caliper
Art No. 264-624

Promo price: **139.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for Caliper
Art No. 264-625

Promo price: **139.00 €***
Suggested retail price: ~~185.00 €*~~

Promotion!



Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit Bluetooth
Art No. 02AZF310

Promo price: **74.90 €***
Suggested retail price: ~~110.00 €*~~

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 10.00 €*
