

Digital ABS Carb. Caliper Inter. Jaws

Item number: 552-192-10

Images



Description

This is a lightweight standard model of Digimatic caliper **with optional interchangeable jaws**.


It offers you the following benefits:

- Its ultra-lightweight design (with carbon fibre reinforced material) reduces total weight by up to 50%.
- It has excellent resistance against water and dust (IP66 protection level) enabling you to use it in machining situations that include splashing coolant fluid.
- Direct readout of inside measurements from the LCD (you can easily set the offset value by using the offset button).
- Preset function lets you set a desired starting point.

Features

Model:	CFC-24"GU
DATA (output with cable) / HOLD (display value):	Yes
Range:	0 - 24 "
Delivered:	In a box with SR44 battery, scriber clamps 05GZA033 (2pcs.)
Max. Permissible Error E MPE:	±0.002"
Max. response speed:	Unlimited
ORIGIN (ABS-Zero):	Yes
OFFSET:	0.25"
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Data output:	Yes
Battery life:	Approx. 5000 hours
Mass:	725 g

Dimensions

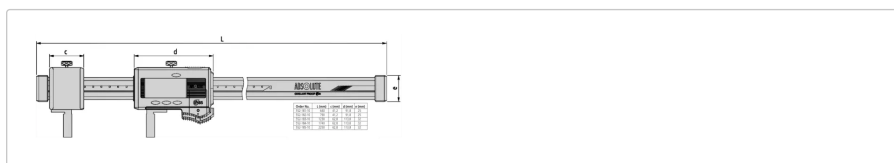

Accessories

Optional accessories:

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Suggested retail price: 340.00 €*




USB-ITPAK

Measuring Jaw, Series 552

2 pcs., Standard Type

Art No. 07CZA056

Suggested retail price: 364.00 €*

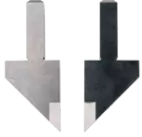


Measuring Jaw, Series 552

1 pcs., Right, Standard Type

Art No. 07CAA044

Suggested retail price: 188.00 €*

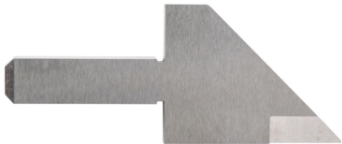

Measuring Jaw, Series 552

1 pcs., Left, Standard Type

Art No. 07CAA045

Suggested retail price: 188.00 €*



Measuring Jaw, Series 552

2 pcs., Centerline Type, Inch

Art No. 07CZA060

Suggested retail price: 445.00 €*



Measuring Jaw, Series 552



1 pcs., Surface Plate Type
Art No. 07CZA044
Suggested retail price: 316.00 €*

Measuring Jaw, Series 552



2 pcs., Inside Point Type, Inch
Art No. 07CZA059
Suggested retail price: 420.00 €*

Measuring Jaw, Series 552



2 pcs., Scriber Type, Inch
Art No. 07CZA061
Suggested retail price: 391.00 €*

Carbide tipped scriber (9 x 9 mm)



Art No. 07GZA000.
Price on application

Digimatic Cable with Data Button IP Type



1m, Caliper Type
Art No. 05CZA624
Suggested retail price: 100.00 €*



Digimatic Cable with Data Button IP Type

2m, Caliper Type
Art No. 05CZA625
Suggested retail price: 107.00 €*



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Caliper Type
Art No. 06AFM380A
Suggested retail price: 141.00 €*



U-WAVE-T, Buzzer Type

Wireless Transmitter
Art No. 02AZD880G
Suggested retail price: 187.00 €*



U-WAVE-T, IP67 Type

Wireless Transmitter
Art No. 02AZD730G
Suggested retail price: 187.00 €*



Connection Cable A for U-WAVE

with Data Button for IP Caliper Type
Art No. 02AZD790A
Suggested retail price: 110.00 €*

Standard accessories:



Scriber Clamp

for 9x9mm Scriber

Art No. 05GZA033

Suggested retail price: 58.00 €*

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*