

## Digital ABS Carb. Caliper Inter. Jaws

Item number: 552-195-10

### Images



### Description

This is a lightweight standard model of Digimatic caliper **with optional interchangeable jaws**.


It offers you the following benefits:

- Its ultra-lightweight design (with carbon fibre reinforced material) reduces total weight by up to 50%.
- It has excellent resistance against water and dust (IP66 protection level) enabling you to use it in machining situations that include splashing coolant fluid.
- Direct readout of inside measurements from the LCD (you can easily set the offset value by using the offset button).
- Preset function lets you set a desired starting point.

### Features

<b>Model:</b>	CFC-80"GU
<b>DATA (output with cable) / HOLD (display value):</b>	Yes
<b>Range:</b>	0 - 80 "
<b>Delivered:</b>	In a box with SR44 battery, scriber clamps 05GZA033 (2pcs.)
<b>Max. Permissible Error E MPE:</b>	$\pm 0,005$ "
<b>Max. response speed:</b>	Unlimited
<b>ORIGIN (ABS-Zero):</b>	Yes
<b>OFFSET:</b>	0.5"
<b>Auto Power OFF after 20 min. non use:</b>	Yes
<b>Low voltage alarm:</b>	Yes
<b>Data output:</b>	Yes
<b>Battery life:</b>	Approx. 5000 hours
<b>Mass:</b>	2280 g

### Dimensions

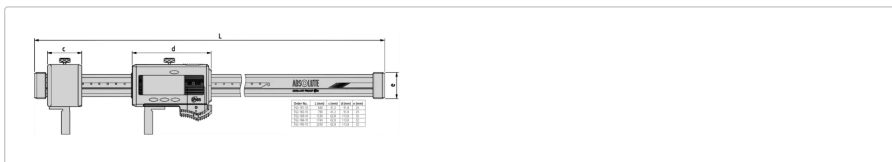

### Accessories

Optional accessories:

## USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Suggested retail price: 340.00 €\*  

---



USB-ITPAK


## Measuring Jaw, Series 552

2 pcs., Standard Type

Art No. 07CZA056

Suggested retail price: 364.00 €\*  

---

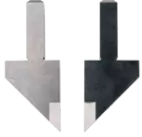


## Measuring Jaw, Series 552

1 pcs., Right, Standard Type

Art No. 07CAA044

Suggested retail price: 188.00 €\*  

---

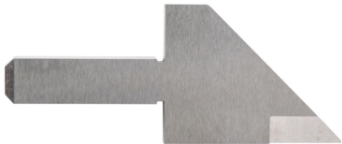

## Measuring Jaw, Series 552

1 pcs., Left, Standard Type

Art No. 07CAA045

Suggested retail price: 188.00 €\*  

---



## Measuring Jaw, Series 552

2 pcs., Centerline Type, Inch

Art No. 07CZA060

Suggested retail price: 445.00 €\*  

---



## Measuring Jaw, Series 552



1 pcs., Surface Plate Type  
Art No. 07CZA044  
Suggested retail price: 316.00 €\*  

---

## Measuring Jaw, Series 552



2 pcs., Inside Point Type, Inch  
Art No. 07CZA059  
Suggested retail price: 420.00 €\*  

---

## Measuring Jaw, Series 552



2 pcs., Scriber Type, Inch  
Art No. 07CZA061  
Suggested retail price: 391.00 €\*  

---

## Carbide tipped scriber (9 x 9 mm)



Art No. 07GZA000.  
Price on application  

---

## Digimatic Cable with Data Button IP Type



1m, Caliper Type  
Art No. 05CZA624  
Suggested retail price: 100.00 €\*  

---



### **Digimatic Cable with Data Button IP Type**

2m, Caliper Type  
Art No. 05CZA625  
Suggested retail price: 107.00 €\*  

---



### **USB Input Tool Direct (Digimatic to USB)**

2m Cable, Digimatic/Digimatic 2, with Data Button IP Caliper Type  
Art No. 06AFM380A  
Suggested retail price: 141.00 €\*  

---



### **U-WAVE-T, Buzzer Type**

Wireless Transmitter  
Art No. 02AZD880G  
Suggested retail price: 187.00 €\*  

---



### **U-WAVE-T, IP67 Type**

Wireless Transmitter  
Art No. 02AZD730G  
Suggested retail price: 187.00 €\*  

---



### **Connection Cable A for U-WAVE**

with Data Button for IP Caliper Type  
Art No. 02AZD790A  
Suggested retail price: 110.00 €\*  

---

Standard accessories:



**Scriber Clamp**

for 9x9mm Scriber

Art No. 05GZA033

Suggested retail price: 58.00 €\*  

---

Spare parts

Consumable spares:



**Battery SR44 1,5 V**

Art No. 938882

Suggested retail price: 7.00 €\*  

---