

Digital ABS Carbon Fibre Caliper

Item number: 552-315-10

Images



Safety
Dust- and
Water-
Protected

www.tuv.com
ID 000022582

ABSOLUTE®

IP66


Description

A Mitutoyo waterproof digital caliper suitable for use in the presence of coolant or cutting oil. Lightweight, carbon-fibre construction for easy handling and equipped with plain stainless-steel jaws. ABSOLUTE System scale for error free, high-speed measurement. SPC data output.

Features

Model:	CFC-60"G
DATA (output with cable) / HOLD (display value):	Yes
Range:	0 - 60 "
Inside measuring from:	25.5 mm/1004"
Delivered:	In a box with SR44 battery
Max. Permissible Error E MPE:	±0,004"
Max. Permissible Error S MPE:	±0,004"
Max. response speed:	Unlimited
ORIGIN (ABS-Zero):	Yes
Low voltage alarm:	Yes
Data output:	Yes
Battery life:	Approx. 5000 hours
Mass:	2160 g

Dimensions

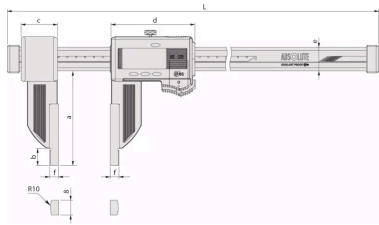

- f:** 0.5 inch
- a:** 150 mm
- b:** 24 mm
- c:** 62.8 mm
- d:** 113.8 mm
- e:** 32 mm
- f:** 10 mm

Accessories

Optional accessories:

Mitutoyo


MiCAT
the standard in world
metrology software
measurLink

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Suggested retail price: 340.00 €*

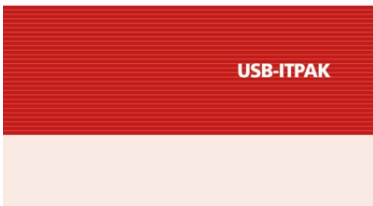

Holders (Clamps) Series 552

2 pcs., >600mm Range

Art No. 914054

Suggested retail price: 214.00 €*



Center to Center Jaws Series 552

2 pcs., (≥10,26mm) Inch

Art No. 914056

Suggested retail price: 272.00 €*



Measuring Jaw

2 pcs., ($\geq 50,9$ mm) Inch
Art No. 914058
Suggested retail price: 312.00 €*

Standard accessories:



Holders (Clamps) Series 552

2 pcs., >600mm Range
Art No. 914054
Suggested retail price: 214.00 €*



Center to Center Jaws Series 552

2 pcs., ($\geq 10,1$ mm) Metric
Art No. 914055
Suggested retail price: 272.00 €*



Inside Groove Jaws Series 552

2 pcs., Metric
Art No. 914057
Suggested retail price: 312.00 €*

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*
