

## Digital ABS Borematic (Internal)

Item number: 568-363-10

### Images



# ABSOLUTE®



### Description

This is a individual unit Three-Point Digimatic Snap Open Bore Gauge. It offers you the following benefits:


- It enables you to take measurements easily and quickly.
- Titanium-coated measuring pins gives you excellent durability and impact resistance.
- 330° rotatable display unit also gives you easy reading at any angle.
- GO/NG tolerance judgement function.

### Features


<b>Model:</b>	SBM-12D
<b>Inch-Metric:</b>	Metric
<b>Digital/Analog:</b>	Digital
<b>Range:</b>	10 - 12 mm
<b>Digital step:</b>	0,001 mm
<b>Max. Permissible Error</b>	±5 μm

**J MPE:**

<b>Power supply:</b>	1 battery SR-44
<b>Battery life:</b>	Approx. 5000 hours
<b>Display:</b>	LCD, character height: 11 mm
<b>Measuring face:</b>	Titanium coated tungsten carbide taper: tungsten carbide
<b>Measuring method:</b>	3-point
<b>ABS / INC (INC ZERO):</b>	Yes
<b>ON/OFF:</b>	Yes
<b>Function lock:</b>	Yes
<b>DATA (output with cable) / HOLD (display value):</b>	Yes
<b>2 x PRESET:</b>	Yes
<b>GO/±NG judgement:</b>	Yes
<b>Delivered:</b>	In a box with SR44 battery, spanner 04GAA857/04GAA858 (2 pcs.)
<b>Data output:</b>	Yes
<b>Mass:</b>	485 g

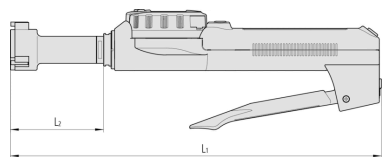**Dimensions**

**a:** 2 mm  
**c:** 2.5 mm  
**L1:** 284 mm  
**L2:** 83 mm

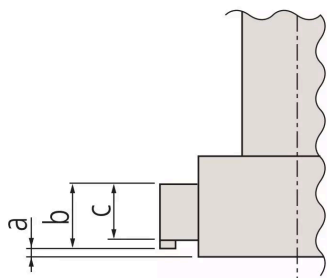

**a:** 2 mm  
**c:** 2.5 mm  
**L1:** 284 mm  
**L2:** 83 mm

**Accessories****Optional accessories:**

Promotion!

**Mitutoyo**

**MiCAT**  
the standard in world  
metrology software  
**MeasurLink**

**USB-ITPAK Vers. 3.0**

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

**Promo price: 268.00 €\***

~~Suggested retail price: 340.00 €\*~~

**USB-ITPAK**



### Digimatic Cable, Flat Straight Type

1 m  
Art No. 905338  
Suggested retail price: 37.00 €\*  

---



### Digimatic Cable, Flat Straight Type

2 m  
Art No. 905409  
Suggested retail price: 44.00 €\*  

---

Promotion!



### USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Flat Straight Type  
Art No. 06AFM380F  
Promo price: **98.00 €\***  
Suggested retail price: ~~124.00 €\*~~



### USB Input Tool Direct (Digimatic to USB)

2m Cable, Flat Straight Type  
Art No. 06ADV380F  
Suggested retail price: 104.00 €\*  

---

Promotion!



### U-WAVE-T, IP67 Type

Wireless Transmitter  
Art No. 02AZD730G  
Promo price: **129.00 €\***  
Suggested retail price: ~~187.00 €\*~~

Promotion!



### U-WAVE-T, Buzzer Type

Wireless Transmitter

Art No. 02AZD880G

Promo price: **129.00 €\***

Suggested retail price: ~~187.00 €\*~~

Promotion!



### Connection Cable F for U-WAVE

Straight, without Data Button

Art No. 02AZD790F

Promo price: **68.00 €\***

Suggested retail price: ~~98.00 €\*~~

### Holtest, Borematic Extension 100mm



for 6-12mm Measuring Range

Art No. 952322

Suggested retail price: **128.00 €\***

#### Spare parts

Consumable spares:



### Battery SR44 1,5 V

Art No. 938882

Suggested retail price: **7.00 €\***