

Digital ABS Borematic (Internal)

Item number: 568-364-10

Images



ABSOLUTE®



Description

This is a individual unit Three-Point Digimatic Snap Open Bore Gauge. It offers you the following benefits:

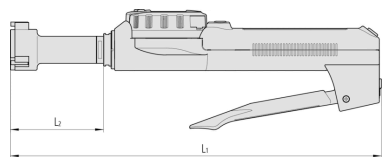
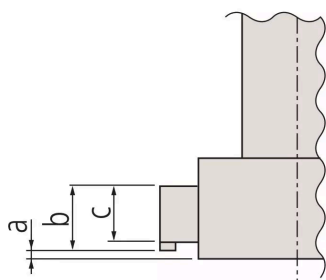
- It enables you to take measurements easily and quickly.
- Titanium-coated measuring pins gives you excellent durability and impact resistance.
- 330° rotatable display unit also gives you easy reading at any angle.
- GO/NG tolerance judgement function.

Features

Model:	SBM-16D
Inch-Metric:	Metric
Digital/Analog:	Digital
Range:	12 - 16 mm
Digital step:	0,001 mm
Max. Permissible Error	±5 µm

J MPE:

Power supply:	1 battery SR-44
Battery life:	Approx. 5000 hours
Display:	LCD, character height: 11 mm
Measuring face:	Titanium coated hardened steel taper: tungsten carbide
Measuring method:	3-point
ABS / INC (INC ZERO):	Yes
ON/OFF:	Yes
Function lock:	Yes
DATA (output with cable) / HOLD (display value):	Yes
2 x PRESET:	Yes
GO/±NG judgement:	Yes
Delivered:	In a box with SR44 battery, spanner 04GAA858 (2 pcs.)
Data output:	Yes
Mass:	475 g

Dimensions**a:** 0.3 mm**b:** 5.6 mm**c:** 3.5 mm**L1:** 255 mm**L2:** 53 mm**a:** 0.3 mm**b:** 5.6 mm**c:** 3.5 mm**L1:** 255 mm**L2:** 53 mm**Accessories**

Optional accessories:

Promotion!

Mitutoyo

MiCAT
the standard in world
metrology software
MeasurLink

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)

Art No. 06AGR543

Promo price: **268.00 €***

Suggested retail price: ~~340.00 €*~~



Digimatic Cable, Flat Straight Type

1 m

Art No. 905338

Suggested retail price: 37.00 €*



Digimatic Cable, Flat Straight Type

2 m

Art No. 905409

Suggested retail price: 44.00 €*

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Flat
Straight Type

Art No. 06AFM380F

Promo price: **98.00 €***

Suggested retail price: ~~124.00 €*~~

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter

Art No. 02AZD730G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter

Art No. 02AZD880G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Promotion!



Connection Cable F for U-WAVE

Straight, without Data Button

Art No. 02AZD790F

Promo price: **68.00 €***

Suggested retail price: ~~98.00 €*~~



Holtest, Borematic Extension 150mm

for 12-20mm Measuring Range

Art No. 952621

Suggested retail price: **120.00 €***

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: **7.00 €***