

## Digital ABS Borematic (Internal)

Item number: 568-366-10

### Images



# ABSOLUTE<sup>®</sup>



### Description

This is a individual unit Three-Point Digimatic Snap Open Bore Gauge. It offers you the following benefits:

- It enables you to take measurements easily and quickly.
- Titanium-coated measuring pins gives you excellent durability and impact resistance.
- 330° rotatable display unit also gives you easy reading at any angle.
- GO/NG tolerance judgement function.

### Features

<b>Model:</b>	SBM-25D
<b>Inch-Metric:</b>	Metric
<b>Digital/Analog:</b>	Digital
<b>Range:</b>	20 - 25 mm
<b>Digital step:</b>	0,001 mm
<b>Max. Permissible Error J MPE:</b>	±6 µm
<b>Power supply:</b>	1 battery SR-44
<b>Battery life:</b>	Approx. 5000 hours
<b>Display:</b>	LCD, character height: 11 mm

**Measuring face:** Titanium coated hardened steel  
taper: tungsten carbide

**Measuring method:** 3-point

**ABS / INC (INC ZERO):** Yes

**ON/OFF:** Yes

**Function lock:** Yes

**DATA (output with cable) / HOLD  
(display value):** Yes

**2 x PRESET:** Yes


**GO/±NG judgement:** Yes

**Delivered:** In a box with SR44 battery, spanner  
04GAA858 (2 pcs.)

**Data output:** Yes

**Mass:** 540 g

## Dimensions

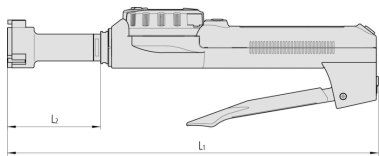


**a:** 0.3 mm

**b:** 8.3 mm

**c:** 5.2 mm

**L1:** 261 mm

**L2:** 59 mm

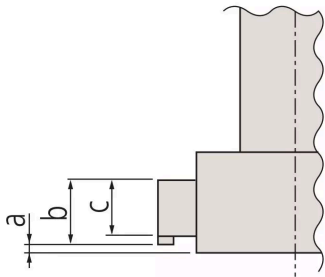

**a:** 0.3 mm

**b:** 8.3 mm

**c:** 5.2 mm

**L1:** 261 mm

**L2:** 59 mm

## Accessories

### Optional accessories:

**Promotion!**

**Mitutoyo**

**MiCAT**  
the standard in world  
metrology software  
**MeasurLink**

**USB-ITPAK Vers. 3.0**  
USB Dongle + Manual (Software available  
Online)  
Art No. 06AGR543  
**Promo price: 268.00 €\*  
Suggested retail price: 340.00 €\*  
USB-ITPAK**



### Digimatic Cable, Flat Straight Type

1 m  
Art No. 905338  
Suggested retail price: 37.00 €\*  

---



### Digimatic Cable, Flat Straight Type

2 m  
Art No. 905409  
Suggested retail price: 44.00 €\*  

---

Promotion!



### USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Flat Straight Type  
Art No. 06AFM380F  
Promo price: **98.00 €\***  
Suggested retail price: ~~124.00 €\*~~

Promotion!



### U-WAVE-T, IP67 Type

Wireless Transmitter  
Art No. 02AZD730G  
Promo price: **129.00 €\***  
Suggested retail price: ~~187.00 €\*~~

Promotion!



### U-WAVE-T, Buzzer Type

Wireless Transmitter  
Art No. 02AZD880G  
Promo price: **129.00 €\***  
Suggested retail price: ~~187.00 €\*~~

Promotion!



## Connection Cable F for U-WAVE

Straight, without Data Button

Art No. 02AZD790F

Promo price: **68.00 €\***

Suggested retail price: ~~98.00 €\*~~



## Holtest, Borematic Extension 150mm

for 20-50mm Measuring Range

Art No. 952622

Suggested retail price: **136.00 €\***

### Spare parts

Consumable spares:



## Battery SR44 1,5 V

Art No. 938882

Suggested retail price: **7.00 €\***