

Digital ABS Borematic (Internal)

Item number: 568-367-10

Images



ABSOLUTE®



Description

This is a individual unit Three-Point Digimatic Snap Open Bore Gauge. It offers you the following benefits:

- It enables you to take measurements easily and quickly.
- Titanium-coated measuring pins gives you excellent durability and impact resistance.
- 330° rotatable display unit also gives you easy reading at any angle.
- GO/NG tolerance judgement function.

Features

Model:	SBM-30D
Inch-Metric:	Metric
Digital/Analog:	Digital
Range:	25 - 30 mm
Digital step:	0,001 mm
Max. Permissible Error J MPE:	±6 µm
Power supply:	1 battery SR-44
Battery life:	Approx. 5000 hours
Display:	LCD, character height: 11 mm

Measuring face: Titanium coated hardened steel
taper: tungsten carbide

Measuring method: 3-point

ABS / INC (INC ZERO): Yes

ON/OFF: Yes

Function lock: Yes

DATA (output with cable) / HOLD (display value): Yes

2 x PRESET: Yes


GO/±NG judgement: Yes

Delivered: In a box with SR44 battery, spanner
04GAA858 (2 pcs.)

Data output: Yes

Mass: 555 g

Dimensions

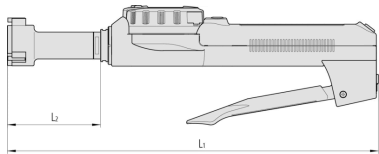


a: 0.3 mm

b: 8.3 mm

c: 5.2 mm

L1: 261 mm

L2: 59 mm

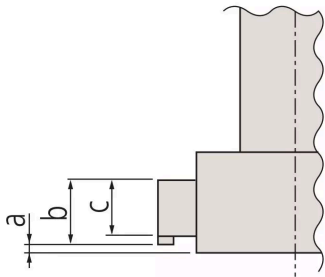

a: 0.3 mm

b: 8.3 mm

c: 5.2 mm

L1: 261 mm

L2: 59 mm

Accessories

Optional accessories:

Promotion!

Mitutoyo

MiCAT
the standard in world
metrology software
MeasurLink

USB-ITPAK Vers. 3.0
USB Dongle + Manual (Software available
Online)
Art No. 06AGR543
Promo price: 268.00 €*
Suggested retail price: ~~340.00 €*~~

USB-ITPAK



Digimatic Cable, Flat Straight Type

1 m
Art No. 905338
Suggested retail price: 37.00 €*



Digimatic Cable, Flat Straight Type

2 m
Art No. 905409
Suggested retail price: 44.00 €*

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Flat Straight Type
Art No. 06AFM380F
Promo price: **98.00 €***
Suggested retail price: ~~124.00 €*~~

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter
Art No. 02AZD730G
Promo price: **129.00 €***
Suggested retail price: ~~187.00 €*~~

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter
Art No. 02AZD880G
Promo price: **129.00 €***
Suggested retail price: ~~187.00 €*~~

Promotion!



Connection Cable F for U-WAVE

Straight, without Data Button

Art No. 02AZD790F

Promo price: **68.00 €***

Suggested retail price: ~~98.00 €*~~



Holtest, Borematic Extension 150mm

for 20-50mm Measuring Range

Art No. 952622

Suggested retail price: **136.00 €***

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: **7.00 €***