

## Digital ABS Borematic (Internal)

Item number: 568-370-10

### Images



# ABSOLUTE®



### Description

This is a individual unit Three-Point Digimatic Snap Open Bore Gauge. It offers you the following benefits:

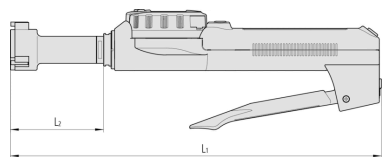
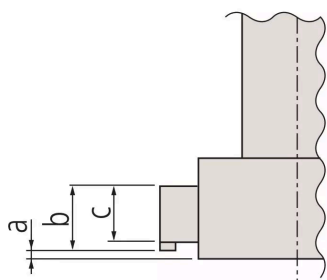
- It enables you to take measurements easily and quickly.
- Titanium-coated measuring pins gives you excellent durability and impact resistance.
- 330° rotatable display unit also gives you easy reading at any angle.
- GO/NG tolerance judgement function.

### Features

|                               |            |
|-------------------------------|------------|
| <b>Model:</b>                 | SBM-63D    |
| <b>Inch-Metric:</b>           | Metric     |
| <b>Digital/Analog:</b>        | Digital    |
| <b>Range:</b>                 | 50 - 63 mm |
| <b>Digital step:</b>          | 0,001 mm   |
| <b>Max. Permissible Error</b> | ±6 µm      |

**J MPE:**

|   |   |
|---|---|
| <b>Power supply:</b>                                    | 1 battery SR-44   |
| <b>Battery life:</b>                                    | Approx. 5000 hours  |
| <b>Display:</b>   | LCD, character height: 11 mm                              |
| <b>Measuring face:</b>                                  | Titanium coated hardened steel<br>taper: tungsten carbide |
| <b>Measuring method:</b>                                | 3-point   |
| <b>ABS / INC (INC ZERO):</b>                            | Yes   |
| <b>ON/OFF:</b>  | Yes   |
| <b>Function lock:</b>                                   | Yes   |
| <b>DATA (output with cable) / HOLD (display value):</b> | Yes   |
| <b>2 x PRESET:</b>                                      | Yes   |
| <b>GO/±NG judgement:</b>                                | Yes   |
| <b>Delivered:</b>                                       | In a box with SR44 battery, spanner<br>04GAA858 (2 pcs.)  |
| <b>Data output:</b>                                     | Yes   |
| <b>Mass:</b>  | 730 g   |

**Dimensions****a:** 0.3 mm**b:** 17 mm**c:** 14 mm**L1:** 277 mm**L2:** 75 mm**a:** 0.3 mm**b:** 17 mm**c:** 14 mm**L1:** 277 mm**L2:** 75 mm**Accessories**

Optional accessories:

Promotion!

Mitutoyo

MiCAT  
the standard in world  
metrology software  
MeasurLink

### USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Promo price: **268.00 €\***

Suggested retail price: ~~340.00 €\*~~



### Digimatic Cable, Flat Straight Type

1 m

Art No. 905338

Suggested retail price: 37.00 €\*



### Digimatic Cable, Flat Straight Type

2 m

Art No. 905409

Suggested retail price: 44.00 €\*

Promotion!



### USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Flat Straight Type

Art No. 06AFM380F

Promo price: **98.00 €\***

Suggested retail price: ~~124.00 €\*~~

Promotion!



### U-WAVE-T, IP67 Type

Wireless Transmitter

Art No. 02AZD730G

Promo price: **129.00 €\***

Suggested retail price: ~~187.00 €\*~~

Promotion!



## U-WAVE-T, Buzzer Type

Wireless Transmitter

Art No. 02AZD880G

Promo price: **129.00 €\***

Suggested retail price: ~~187.00 €\*~~

Promotion!



## Connection Cable F for U-WAVE

Straight, without Data Button

Art No. 02AZD790F

Promo price: **68.00 €\***

Suggested retail price: ~~98.00 €\*~~



## Holtest, Borematic Extension 150mm

for 50-300mm Measuring Range

Art No. 952623

Suggested retail price: **216.00 €\***

### Spare parts

Consumable spares:



## Battery SR44 1,5 V

Art No. 938882

Suggested retail price: **7.00 €\***