

## Digital ABS Borematic (Internal)

Item number: 568-461-10

### Images



# ABSOLUTE®



### Description


A unique, Mitutoyo digital bore gauge that enables measurements to be made more accurately and more quickly than ever before. Trigger-grip operation ensures fast, easy measurement and a constant measurement force for maximum repeatability on the shop floor. The Borematic ABSOLUTE scale retains the last setting for the life of the battery, therefore repeated setting is not necessary. Large-digit, rotatable LCD display aids convenient, error-free reading.

### Features


<b>Model:</b>	SBM-0.35"D
<b>Inch-Metric:</b>	Inch/Metric
<b>Digital/Analog:</b>	Digital
<b>Range:</b>	0,275 - 0,35 "
<b>Digital step:</b>	0,00005" / 0,001 mm
<b>Power supply:</b>	1 battery SR-44
<b>Battery life:</b>	Approx. 5000 hours
<b>Display:</b>	LCD, character height: 11 mm
<b>Measuring face:</b>	Titanium coated tungsten carbide taper: tungsten carbide
<b>Measuring method:</b>	3-point
<b>ABS / INC (INC ZERO):</b>	Yes

<b>ON/OFF:</b>	Yes
<b>Function lock:</b>	Yes
<b>DATA (output with cable) / HOLD (display value):</b>	Yes
<b>2 x PRESET:</b>	Yes
<b>GO/±NG judgement:</b>	Yes
<b>Delivered:</b>	In a box with SR44 battery, spanner 04GAA857/04GAA858 (2 pcs.)
<b>Data output:</b>	Yes
<b>Mass:</b>	480 g

## Dimensions

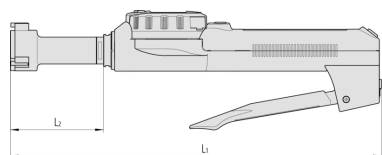

**a:** 2 mm  
**c:** 2.5 mm  
**L1:** 284 mm  
**L2:** 83 mm

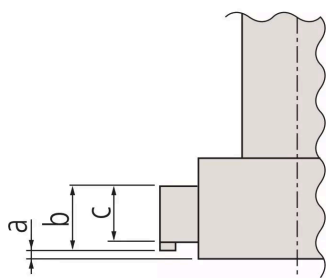


**a:** 2 mm  
**c:** 2.5 mm  
**L1:** 284 mm  
**L2:** 83 mm

## Accessories

### Optional accessories:

Promotion!



the standard in world metrology software  
**MeasurLink**

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Promo price: 268.00 €\*  
Suggested retail price: ~~340.00 €\*~~



USB-ITPAK



### Digimatic Cable, Flat Straight Type

1 m  
Art No. 905338  
Suggested retail price: 37.00 €\*



## Digimatic Cable, Flat Straight Type

2 m  
Art No. 905409  
Suggested retail price: 44.00 €\*  
~~44.00 €\*~~

Promotion!



## USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Flat Straight Type  
Art No. 06AFM380F  
Promo price: 98.00 €\*  
Suggested retail price: 124.00 €\*

Promotion!



## U-WAVE-T, IP67 Type

Wireless Transmitter  
Art No. 02AZD730G  
Promo price: 129.00 €\*  
Suggested retail price: 187.00 €\*

Promotion!



## U-WAVE-T, Buzzer Type

Wireless Transmitter  
Art No. 02AZD880G  
Promo price: 129.00 €\*  
Suggested retail price: 187.00 €\*

 
Promotion!



## Connection Cable F for U-WAVE

Straight, without Data Button  
Art No. 02AZD790F  
Promo price: 68.00 €\*  
Suggested retail price: 98.00 €\*

## Holtest, Borematic Extension 100mm



for 6-12mm Measuring Range  
Art No. 952322  
Suggested retail price: 128.00 €\*  

---

### Spare parts

#### Consumable spares:

---



## Battery SR44 1,5 V

Art No. 938882  
Suggested retail price: 7.00 €\*  

---