

Digital ABS Borematic (Internal)

Item number: 568-463

Images



ABSOLUTE®



Description

A unique, Mitutoyo digital bore gauge that enables measurements to be made more accurately and more quickly than ever before. Trigger-grip operation ensures fast, easy measurement and a constant measurement force for maximum repeatability on the shop floor. The Borematic ABSOLUTE scale retains the last setting for the life of the battery, therefore repeated setting is not necessary. Large-digit, rotatable LCD display aids convenient, error-free reading.

Features

Inch-Metric:	Inch/Metric
Digital/Analog:	Digital
Range:	0,425 - 0,5 "
Digital step:	0.00005" / 0.001 mm
Power supply:	1 battery SR-44
Battery life:	Approx. 5000 hours
Display:	LCD, character height: 11 mm

Measuring face: Titanium coated tungsten carbide
taper: tungsten carbide

Measuring method: 3-point

ABS / INC (INC ZERO): Yes

ON/OFF: Yes

Function lock: Yes

DATA (output with cable) / HOLD (display value): Yes

2 x PRESET: Yes


GO/±NG judgement: Yes

Delivered: In a box with SR44 battery, spanner
04GAA857/04GAA858 (2 pcs.)

Data output: Yes

Mass: 485 g

Dimensions

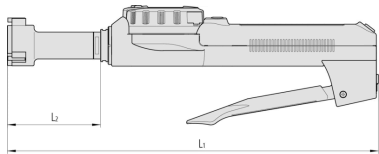


a: 2 mm

c: 2.5 mm

L1: 284 mm

L2: 83 mm

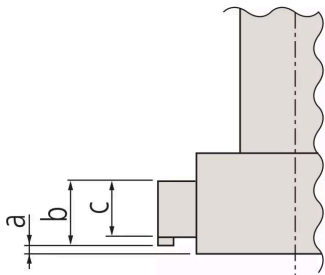

a: 2 mm

c: 2.5 mm

L1: 284 mm

L2: 83 mm

Accessories

Optional accessories:

Promotion!

Mitutoyo

MiCAT
the standard in world
metrology software
MeasurLink

USB-ITPAK Vers. 3.0
USB Dongle + Manual (Software available
Online)
Art No. 06AGR543
**Promo price: 268.00 €*
Suggested retail price: 340.00 €***

USB-ITPAK



Digimatic Cable, Flat Straight Type

1 m
Art No. 905338
Suggested retail price: 37.00 €*



Digimatic Cable, Flat Straight Type

2 m
Art No. 905409
Suggested retail price: 44.00 €*

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Flat Straight Type
Art No. 06AFM380F
Promo price: **98.00 €***
Suggested retail price: ~~124.00 €*~~

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter
Art No. 02AZD730G
Promo price: **129.00 €***
Suggested retail price: ~~187.00 €*~~

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter
Art No. 02AZD880G
Promo price: **129.00 €***
Suggested retail price: ~~187.00 €*~~

Promotion!



Connection Cable F for U-WAVE

 
Straight, without Data Button

Art No. 02AZD790F

Promo price: **68.00 €***

Suggested retail price: ~~98.00 €*~~

Holtest, Borematic Extension 100mm



for 6-12mm Measuring Range

Art No. 952322

Suggested retail price: **128.00 €***

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: **7.00 €***