

Digital ABS Borematic (Internal)

Item number: 568-464-10

Images



ABSOLUTE®



Description

This is a individual unit Three-Point Digimatic Snap Open Bore Gauge. It offers you the following benefits:


- It enables you to take measurements easily and quickly.
- Titanium-coated measuring pins gives you excellent durability and impact resistance.
- 330° rotatable display unit also gives you easy reading at any angle.
- GO/NG tolerance judgement function.

Features

Model:	SBM-0.65"D
Digital/Analog:	Digital
Inch-Metric:	Inch/Metric
Range:	0,5 - 0,65 "
Digital step:	0,00005" / 0,001 mm
Display:	LCD, character height: 11 mm
Measuring face:	Titanium coated
Measuring method:	3-point
Power supply:	1 battery SR-44
Battery life:	Approx. 5000 hours

ABS / INC (INC ZERO):	Yes
ON/OFF:	Yes
Function lock:	Yes
DATA (output with cable) / HOLD (display value):	Yes
2 x PRESET:	Yes
Delivered:	In a box with SR44 battery, spanner 04GAA858 (2 pcs.)
Data output:	Yes
GO/±NG judgement:	Yes
Mass:	475 g

Dimensions

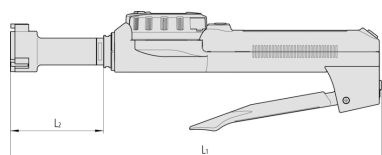


a: 0.3 mm

b: 5.6 mm

c: 3.5 mm

L1: 255 mm

L2: 53 mm

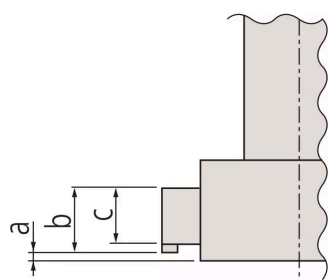

a: 0.3 mm

b: 5.6 mm

c: 3.5 mm

L1: 255 mm

L2: 53 mm

Accessories

Optional accessories:

Promotion!

Mitutoyo

MiCAT
the standard in world
metrology software
MeasurLink

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Promo price: 259.00 €*

Suggested retail price: ~~340.00 €*~~

USB-ITPAK



Digimatic Cable, Flat Straight Type

1m
Art No. 905338
Suggested retail price: 37.00 €*



Digimatic Cable, Flat Straight Type

2m
Art No. 905409
Suggested retail price: 44.00 €*

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Flat Straight Type
Art No. 06AFM380F
Promo price: **98.90 €***
Suggested retail price: ~~124.00 €*~~

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter
Art No. 02AZD730G
Promo price: **129.00 €***
Suggested retail price: ~~187.00 €*~~

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter
Art No. 02AZD880G
Promo price: **129.00 €***
Suggested retail price: ~~187.00 €*~~

Promotion!



Connection Cable F for U-WAVE

Straight, without Data Button

Art No. 02AZD790F

Promo price: **63.90 €***

Suggested retail price: ~~98.00 €*~~



Holtest, Borematic Extension 150mm

for 12-20mm Measuring Range

Art No. 952621

Suggested retail price: **118.00 €***

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: **10.00 €***