

Digital ABS Borematic (Internal)

Item number: 568-468

Images



ABSOLUTE®



Description


A unique, Mitutoyo digital bore gauge that enables measurements to be made more accurately and more quickly than ever before. Trigger-grip operation ensures fast, easy measurement and a constant measurement force for maximum repeatability on the shop floor. The Borematic ABSOLUTE scale retains the last setting for the life of the battery, therefore repeated setting is not necessary. Large-digit, rotatable LCD display aids convenient, error-free reading.

Features

Inch-Metric:	Inch/Metric
Digital/Analog:	Digital
Range:	1,2 - 1,6 "
Digital step:	0.00005" / 0.001 mm
Power supply:	1 battery SR-44
Battery life:	Approx. 5000 hours
Display:	LCD, character height: 11 mm
Measuring face:	Titanium coated
Measuring method:	3-point
ABS / INC (INC ZERO):	Yes
ON/OFF:	Yes
Function lock:	Yes

DATA (output with cable) / HOLD (display value):	Yes
2 x PRESET:	Yes
GO/±NG judgement:	Yes
Delivered:	In a box with SR44 battery, spanner 04GAA858 (2 pcs.)
Data output:	Yes
Mass:	565 g

Dimensions

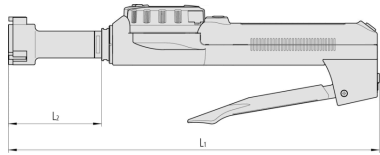


a: 0.3 mm

b: 13 mm

c: 10 mm

L1: 269 mm

L2: 67 mm

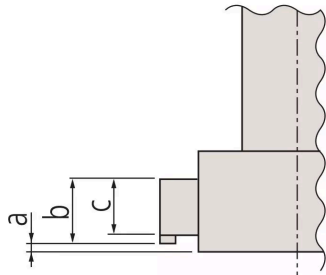

a: 0.3 mm

b: 13 mm

c: 10 mm



L1: 269 mm

L2: 67 mm


Accessories

Optional accessories:

Promotion!

the standard in world metrology software



USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Promo price: **268.00 €***

Suggested retail price: ~~340.00 €*~~

USB-ITPAK



Digimatic Cable, Flat Straight Type

1 m

Art No. 905338

Suggested retail price: 37.00 €*



Digimatic Cable, Flat Straight Type

2 m
Art No. 905409
Suggested retail price: 44.00 €*
~~44.00 €*
44.00 €*~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Flat Straight Type
Art No. 06AFM380F
Promo price: 98.00 €*
Suggested retail price: 124.00 €*
~~124.00 €*
124.00 €*~~

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter
Art No. 02AZD730G
Promo price: 129.00 €*
Suggested retail price: 187.00 €*
~~187.00 €*
187.00 €*~~

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter
Art No. 02AZD880G
Promo price: 129.00 €*
Suggested retail price: 187.00 €*
~~187.00 €*
187.00 €*~~

Promotion!



Connection Cable F for U-WAVE

Straight, without Data Button
Art No. 02AZD790F
Promo price: 68.00 €*
Suggested retail price: 98.00 €*
~~98.00 €*
98.00 €*~~



Holtest, Borematic Extension 150mm

for 20-50mm Measuring Range

Art No. 952622

Suggested retail price: 136.00 €*

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*
