

Digital ABS Borematic (Internal) Set

Item number: 568-928

Images



ABSOLUTE®



Description

Mitutoyo Interchangeable-Head Bore Gauge Set .275-.5"

Features

Inch-Metric:	Inch/Metric
Digital/Analog:	Digital
Range:	0,275 - 0,5 "
Digital step:	0.00005" / 0.001 mm
Individual ranges:	0.275-0.35" 0.35-0.425" 0.425-0.5"
Power supply:	1 battery SR-44
Battery life:	Approx. 5000 hours
Display:	LCD, character height: 11 mm
Measuring face:	Titanium coated carbide taper: tungsten carbide
Measuring method:	3-point
Setting rings included:	Ø0.35" (177-179) Ø0.425" (177-283)
ABS / INC (INC ZERO):	Yes

ON/OFF:	Yes
Function lock:	Yes
DATA (output with cable) / HOLD (display value):	Yes
2 x PRESET:	Yes
GO/±NG judgement:	Yes
Delivered:	In a box with SR44 battery, spanner 04GAA857/04GAA858 (2 pcs.), setting rings (2 pcs.)
Data output:	Yes
Mass:	530 g

Accessories

Optional accessories:

Promotion!

Mitutoyo

MiCAT
the standard in world
metrology software
MeasurLink®


USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)

Art No. 06AGR543

Promo price: 268.00 €*

Suggested retail price: ~~340.00 €*~~

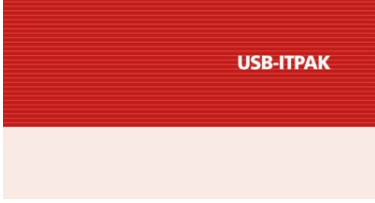

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882
Suggested retail price: 7.00 €*