

Digital ABS Height Gauge

Item number: 570-227

Images



ABSOLUTE®

Description

This Digimatic height gauge is very precise and reliable, and offers you the following benefits:


- Its built-in ABSOLUTE linear encoder means you don't have to set the reference point at every power-on, improving reliability as over-speed errors cannot occur.
- Fine-adjustment gives you precise positioning.
- A carbide-tipped scriber is provided.

Features

Model:	HDS-20C
Digital/Analog:	Digital
Range:	0 - 200 mm
Digital step:	0,01 mm
Delivered:	In a carton box, with carbide tipped scriber, scriber clamp, SR44 battery
Max. Permissible Error E MPE:	±0,03 mm
Fine adjustment:	4 mm
Max. Permissible Error J MPE:	±0,03 mm
Remarks:	2 x PRESET
Scale:	ABSOLUTE electrostatic linear encoder
Display:	LCD, 6-digit
Max. response speed:	Unlimited
ON/OFF:	Yes
ABS / INC (INC ZERO):	Yes
PRESET:	Yes
ORIGIN (ABS-Zero):	Yes
DATA (output with cable) / HOLD (display value):	Yes

Low voltage alarm:	Yes
±SWITCHING:	Yes
Inch-Metric:	Metric
Power supply:	1 battery SR-44
Battery life:	approx. 5000 hours
Mass:	1.3 kg

Dimensions

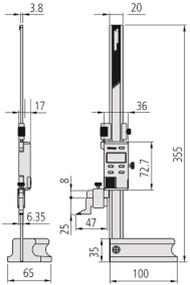

Accessories

Optional accessories:

Promotion!




the standard in world metrology software
MeasurLink

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Promo price: 268.00 €*

~~Suggested retail price: 340.00 €*~~



USB-ITPAK



Digimatic Cable, Flat Straight Type

1 m
Art No. 905338
Suggested retail price: 37.00 €*



Digimatic Cable, Flat Straight Type

2 m
Art No. 905409
Suggested retail price: 44.00 €*

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Flat
Straight Type
Art No. 06AFM380F

Promo price: **98.00 €***

Suggested retail price: ~~124.00 €*~~

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter
Art No. 02AZD880G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter
Art No. 02AZD730G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Promotion!



Connection Cable F for U- WAVE

Straight, without Data Button
Art No. 02AZD790F

Promo price: **68.00 €***


Suggested retail price: ~~98.00 €*~~



Holding Bar for Swivel Clamp

6,25x12,7mm, 2" Length
Art No. 953639

Suggested retail price: 19.50 €*

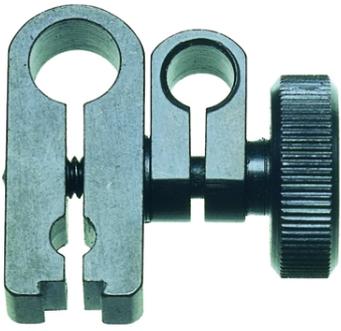

Swivel Clamp

for D= 4/8mm, Dovetail
Art No. 900321
Suggested retail price: 26.50 €*



Center Master

for 6,35x12,7mm
Art No. 900581
Suggested retail price: 161.00 €*



Depth Gauge Attachment

for 12,7mm x 6,35mm
Art No. 900878
Suggested retail price: 59.00 €*

Standard accessories:



Scriber Clamp

for 6,35x12,7mm Scriber
Art No. 901338
Suggested retail price: 23.80 €*



Carbide Tipped Scriber

6,35x12,7mm, 47mm Length

Art No. 900173

Suggested retail price: 87.00 €*

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*
