

Digital ABS Height Gauge

Item number: 570-248

Images



ABSOLUTE[®]

Description

A Mitutoyo digital height gauge with fine adjustment. ABSOLUTE linear encoder eliminates overspeed errors. SPC data output.

Features

Model:	HDS-40"C
Digital/Analog:	Digital
Range:	0 - 40 "
Digital step:	0.0005"/0.01 mm
Delivered:	In a carton box, with carbide tipped scribe, scribe clamp, SR44 battery
Max. Permissible Error E MPE:	$\pm 0,003"/\pm 0,07$ mm
Max. Permissible Error J MPE:	± 0.07 mm/0.003"
Scale:	ABSOLUTE electrostatic linear encoder
Display:	LCD, 6-digit
Max. response speed:	Unlimited
ON/OFF:	Yes
ABS / INC (INC ZERO):	Yes
PRESET:	Yes
ORIGIN (ABS-Zero):	Yes
DATA (output with cable) / HOLD (display value):	Yes
Low voltage alarm:	Yes
±SWITCHING:	Yes
Inch-Metric:	Inch/Metric
Power supply:	1 battery SR-44

Battery life:

approx. 5000 hours

Mass:

16.8 kg

Accessories

Optional accessories:

Promotion!

Mitutoyo

MiCAT

the standard in world
metrology software
MeasurLink®

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)

Art No. 06AGR543

Promo price: **268.00 €***

Suggested retail price: ~~340.00 €*~~



Digimatic Cable, Flat Straight Type

1 m

Art No. 905338

Suggested retail price: 37.00 €*



Digimatic Cable, Flat Straight Type

2 m

Art No. 905409

Suggested retail price: 44.00 €*

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Flat
Straight Type

Art No. 06AFM380F

Promo price: **98.00 €***

Suggested retail price: ~~124.00 €*~~

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter

Art No. 02AZD880G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter

Art No. 02AZD730G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Promotion!



Connection Cable F for U-WAVE

Straight, without Data Button

Art No. 02AZD790F

Promo price: **68.00 €***

Suggested retail price: ~~98.00 €*~~



Holding Bar for Swivel Clamp

9x9mm, 50mm Length

Art No. 953638

Suggested retail price: **24.00 €***




Holding Bar for Swivel Clamp

9x9mm, 100mm Length

Art No. 900209

Suggested retail price: **17.30 €***

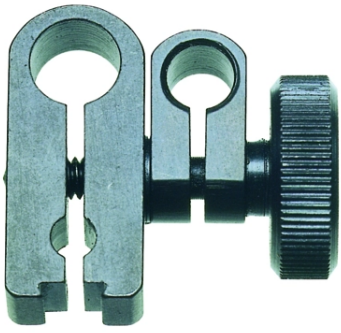

Swivel Clamp

for D= 4/8mm, Dovetail
Art No. 900321
Suggested retail price: 26.50 €*



Center Master

for 9x9mm
Art No. 951144
Suggested retail price: 183.00 €*



Depth Gauge Attachment

for 9x9 mm
Art No. 900764
Suggested retail price: 59.00 €*



Contact Sensor

for Height Gauges
Art No. 900872
Suggested retail price: 135.00 €*

Standard accessories:



Scriber Clamp

for 6,35x12,7mm Scriber
Art No. 901385
Suggested retail price: 23.80 €*

Carbide Tipped Scriber

6,35x12,7mm, 150mm Length
Art No. 905201
Suggested retail price: 137.00 €*



Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882
Suggested retail price: 7.00 €*