

Digital ABS Height Gauge

Item number: 570-413

Images





ABSOLUTE®

Description


This Digimatic height gauge is very precise and reliable, and offers you the following benefits:

- Its built-in ABSOLUTE linear encoder means you don't have to set the reference point at every power-on, improving reliability as over-speed errors cannot occur.
- It comes with large and smooth-acting slider hand wheel
- A carbide-tipped scriber is provided.
- A large display and buttons for easy operability.

Features

Model:	HDS-18"CX
Digital/Analog:	Digital
Delivered:	In a carton box, with carbide tipped scriber, scriber clamp, SR44 battery
Range:	0 - 18" "
Digital step:	0.0005"/0.01 mm
Max. Permissible Error E MPE:	±0,002"/±0,05 mm
Scale:	ABSOLUTE capacitance type linear encoder
Display:	LCD, character height 12 mm
Max. response speed:	Unlimited
ON/OFF:	Yes
ABS / INC (INC ZERO):	Yes
ORIGIN (ABS-Zero):	Yes
DATA (output with cable) / HOLD (display value):	Yes
Low voltage alarm:	Yes
Mm / inch switching:	Yes
Inch-Metric:	Inch/Metric
Power supply:	1 battery SR-44
Battery life:	Approx. 5 years under normal use

Dimensions

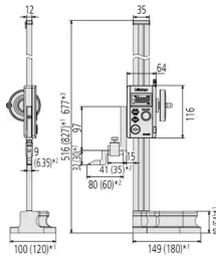

*1 0 to 450 mm, 0 to 600 mm
 *2 Inch model
 *3 0 to 450 mm

- a: 181 mm
- b: 142 mm
- c: 74,1 mm
- L: 662 mm

Accessories

Optional accessories:

Promotion!




the standard in world metrology software



USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Promo price: 259.00 €*

~~Suggested retail price: 340.00 €*~~

USB-ITPAK



Digimatic Cable, Flat Straight Type

1m

Art No. 905338

Suggested retail price: 37.00 €*



Digimatic Cable, Flat Straight Type

2m

Art No. 905409

Suggested retail price: 44.00 €*

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Flat Straight Type

Art No. 06AFM380F

Promo price: 98.90 €*

~~Suggested retail price: 124.00 €*~~

Promotion!



U-WAVE-T, Buzzer Type

Wireless Transmitter

Art No. 02AZD880G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Promotion!



U-WAVE-T, IP67 Type

Wireless Transmitter

Art No. 02AZD730G

Promo price: **129.00 €***

Suggested retail price: ~~187.00 €*~~

Promotion!



Connection Cable F for U-WAVE

Straight, without Data Button

Art No. 02AZD790F

Promo price: **63.90 €***

Suggested retail price: ~~98.00 €*~~



Holding Bar for Swivel Clamp

6,25x12,7mm, 2" Length

Art No. 953639

Suggested retail price: **19.00 €***



Swivel Clamp

for D= 4/9,52mm, Dovetail

Art No. 900322

Suggested retail price: **36.00 €***

Center Master

for 6,35x12,7mm
Art No. 900581
Suggested retail price: 161.00 €*




Depth Gauge Attachment

for 12,7mm x 6,35mm
Art No. 900878
Suggested retail price: 59.00 €*




Contact Sensor

for Height Gauges
Art No. 900872
Suggested retail price: 135.00 €*




Standard accessories:

Carbide Tipped Scriber

6,35x12,7mm, 60mm Length
Art No. 900258
Suggested retail price: 81.00 €*






Scriber Clamp

for 6,35x12,7mm Scriber
Art No. 901385
Suggested retail price: 28.00 €*



Vinyl Cover Series 192

600mm
Art No. 450292
Suggested retail price: 13.00 €*

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882
Suggested retail price: 10.00 €*