

Digital ABS Depth Gauge IP67

Item number: 571-252-20

Images



Dust- and
Water-
Protected

www.tuv.com
ID 0000045042

ABSOLUTE®

IP67

Description

This Digital Depth Gauge is IP67 coolant proof and offers you the following benefits:

- ABSOLUTE System gives you reliable measurements.
- Its base and measuring faces are hardened and micro-lapped for robustness.
- It has excellent resistance against water and dust (IP67 protection level) enabling you to use it in machining situations that include splashing coolant fluid.
- Extremely resistant to both coolants and lubricants.

Features

Inch-Metric:	Metric
Digital/Analog:	Digital
Range:	0 - 200 mm
Digital step:	0,01 mm
Max. Permissible Error E MPE:	±0,02 mm
Auto Power OFF after 20 min. non use:	Yes
Max. response speed:	Unlimited
Battery life:	Approx. 5 years
Power supply:	1 battery SR-44
Repeatability:	0.01 mm
Display:	LCD, Character Height 9 mm
Base (W x T):	100 x 6 mm
Delivered:	In a box with SR44 battery


ORIGIN (ABS-Zero): Yes

Low voltage alarm: Yes

Data output: Yes

Mass: 219 g

Dimensions

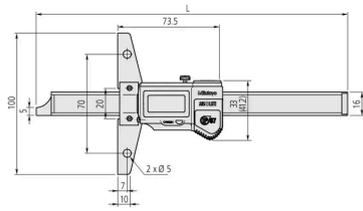

L: 289 mm

Accessories

Optional accessories:



Digimatic Cable with Data Button IP Type

1m, Caliper Type
Art No. 05CZA624
Suggested retail price: 100.00 €*



Digimatic Cable with Data Button IP Type

2m, Caliper Type
Art No. 05CZA625
Suggested retail price: 107.00 €*

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Caliper Type
Art No. 06AFM380A
Promo price: **109.00 €***
Suggested retail price: ~~141.00 €*~~

Promotion!



U-WAVE fit, IP67 Type

Wireless Transmitter for Caliper
Art No. 264-620

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit, Buzzer Type

Wireless Transmitter for Caliper
Art No. 264-621

Promo price: **129.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, IP67 Type

Wireless Transmitter for Caliper
Art No. 264-624

Promo price: **139.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



U-WAVE fit Bluetooth, Buzzer Type

Wireless Transmitter for Caliper
Art No. 264-625

Promo price: **139.00 €***

Suggested retail price: ~~185.00 €*~~

Promotion!



Connection Unit for IP Caliper, Micrometer

with Data Button for U-WAVE fit, U-WAVE fit Bluetooth

Art No. 02AZF310

Promo price: **74.90 €***

Suggested retail price: ~~110.00 €*~~

Extension Base, Depth Gauge

180mm width for up to 300mm Range

Art No. 900370

Suggested retail price: 69.00 €*


Extension Base, Depth Gauge

260mm width for up to 300mm Range

 
Art No. 900371

Suggested retail price: 93.00 €*


Extension Base, Depth Gauge

320mm width for up to 300mm Range

Art No. 900372

Suggested retail price: 107.00 €*


Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 10.00 €*
