


ABSOLUTE Digimatic Scale Unit

Item number: 572-497-10

Images

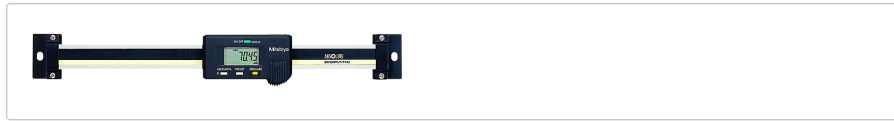

Description

- The ZERO point is set only once and is stored as the ABSOLUTE ZERO point until the next battery replacement
- You can make the highest precision measurements even at the highest drive speed.

Features

Inch-Metric:	Inch/Metric
Accuracy:	0.07 mm/0.0025"
ON/OFF:	Yes
DATA (output with cable) / HOLD (display value):	Yes
Low voltage alarm:	Yes
Data output:	Yes
Diameter function:	Yes
ORIGIN:	Yes
Max response speed:	Unlimited
Functions:	Horizontal multi-function type with diameter displaying function

Dimensions

L1: 1174 mm
L2: 1150 mm
H: 18.6 mm
t: 10 mm

Accessories

Optional accessories:

Promotion!



Connection Cable C for U-WAVE

Straight, with Data Button

Art No. 02AZD790C

Promo price: **72.00 €***

Suggested retail price: ~~105.00 €*~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Straight, with Data Button

Art No. 06AFM380C

Promo price: **98.00 €***

Suggested retail price: ~~124.00 €*~~



Digimatic Cable, Flat Straight Type

1 m

Art No. 905338

Suggested retail price: 37.00 €*



Digimatic Cable, Flat Straight Type

2 m

Art No. 905409

Suggested retail price: 44.00 €*



Digimatic Cable, Flat L-Shape Type

1 m

Art No. 905689

Suggested retail price: 40.00 €*



Digimatic Cable, Flat L-Shape Type

2 m
Art No. 905690
Suggested retail price: 46.00 €*



Digimatic Cable, Flat L-Shape Right Type

1 m
Art No. 905691
Suggested retail price: 40.00 €*



Digimatic Cable, Flat L-Shape Right Type

2 m
Art No. 905692
Suggested retail price: 46.00 €*



Digimatic Cable, Flat L-Shape Left Type

1 m
Art No. 905693
Suggested retail price: 40.00 €*



Digimatic Cable, Flat L-Shape Left Type

2 m
Art No. 905694
Suggested retail price: 46.00 €*

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*
