

ABS Digimatic Scale Unit 1000

mm

Item number: 572-587-10

Images



Description


This unit has an ABSOLUTE capacitive-type scale.

- The ZERO point is set only once and is stored as the absolute ZERO point until the next battery replacement.
- The display has large characters, making it easy to read.
- Diameter measurement function is included.

Features

Model:	SDV-100F
Inch-Metric:	Metric
Accuracy:	0,07 mm
ON/OFF:	Yes
DATA (output with cable) / HOLD (display value):	Yes
Low voltage alarm:	Yes
Data output:	Yes
Diameter function:	Yes
Max. drive speed:	Unlimited
ORIGIN:	Yes
Mass:	2.04 kg

Dimensions

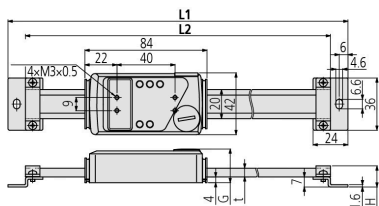

L1: 1174 mm

L2: 1150 mm

H: 18.6 mm

t: 10 mm

Accessories

Optional accessories:

Promotion!



Connection Cable C for U-WAVE

Straight, with Data Button

Art No. 02AZD790C

Promo price: **63.90 €***

Suggested retail price: ~~105.00 €*~~

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, Straight, with Data Button

Art No. 06AFM380C

Promo price: **98.90 €***

Suggested retail price: ~~124.00 €*~~



Digimatic Cable, Flat Straight Type

1m

Art No. 905338

Suggested retail price: 37.00 €*



Digimatic Cable, Flat Straight Type

2m

Art No. 905409

Suggested retail price: 44.00 €*



Digimatic Cable, Flat L-Shape Type

1m

Art No. 905689

Suggested retail price: 40.00 €*



Digimatic Cable, Flat L-Shape Type

2m
Art No. 905690
Suggested retail price: 46.00 €*



Digimatic Cable, Flat L-Shape Right Type

1m
Art No. 905691
Suggested retail price: 40.00 €*



Digimatic Cable, Flat L-Shape Right Type

2m
Art No. 905692
Suggested retail price: 46.00 €*



Digimatic Cable, Flat L-Shape Left Type

1m
Art No. 905693
Suggested retail price: 40.00 €*



Digimatic Cable, Flat L-Shape Left Type

2m
Art No. 905694
Suggested retail price: 46.00 €*

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 10.00 €*
