

## ABSOLUTE Digimatic Scale Unit

Item number: 572-600

### Images



**ABSOLUTE<sup>®</sup>**  
**IP66**

### Description


You can use this scale unit in adverse environments with water and cutting oil due to its new detection method (electromagnetic induction).

- Specially designed output cables are developed to maintain the water resistant structure.
- You will have no overspeed error since the ABSOLUTE scale does not depend on counting scale graduations.
- Once an absolute zero (origin) point is set, the Digimatic Scale Unit shows the absolute distance from this point when it is powered on, rather than „0“.

### Features

<b>Model:</b>	SD-10G
<b>Inch-Metric:</b>	Metric
<b>Accuracy:</b>	0,03 mm
<b>ORIGIN (ABS-Zero):</b>	Yes
<b>Low voltage alarm:</b>	Yes
<b>Repeatability:</b>	0.01 mm
<b>Max. response speed:</b>	Unlimited
<b>Data output:</b>	Yes
<b>Mass:</b>	0.39 kg

### Dimensions

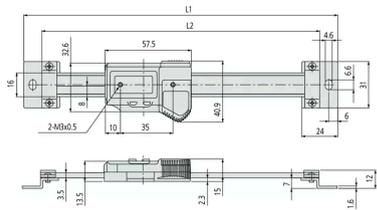

**L1:** 209 mm

**L2:** 185 mm

## Accessories

### Optional accessories:

Promotion!



### Connection Cable A for U-WAVE

with Data Button for IP Caliper Type  
Art No. 02AZD790A

Promo price: **72.90 €\***

Suggested retail price: ~~110.00 €\*~~



### Digimatic Cable with Data Button IP Type

1m, Caliper Type

Art No. 05CZA624

Suggested retail price: 100.00 €\*



### Digimatic Cable with Data Button IP Type

2m, Caliper Type

Art No. 05CZA625

Suggested retail price: 107.00 €\*

Promotion!



### USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Caliper Type

Art No. 06AFM380A

Promo price: **109.00 €\***

Suggested retail price: ~~141.00 €\*~~

**Spare parts**

Consumable spares:

---



**Battery SR44 1,5 V**

Art No. 938882

Suggested retail price: 10.00 €\*  

---