

ABSOLUTE Digimatic Scale Unit

Item number: 572-601

Images



Description


You can use this scale unit in adverse environments with water and cutting oil due to its new detection method (electromagnetic induction).

- Specially designed output cables are developed to maintain the water resistant structure.
- You will have no overspeed error since the ABSOLUTE scale does not depend on counting scale graduations.
- Once an absolute zero (origin) point is set, the Digimatic Scale Unit shows the absolute distance from this point when it is powered on, rather than „0“.

Features

Model:	SD-15G
Inch-Metric:	Metric
Accuracy:	0,03 mm
ORIGIN (ABS-Zero):	Yes
Low voltage alarm:	Yes
Repeatability:	0.01 mm
Max. response speed:	Unlimited
Data output:	Yes
Mass:	0.41 kg

Dimensions

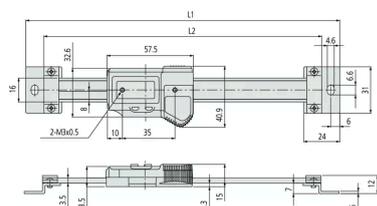

L1: 259 mm

L2: 235 mm

Accessories

Optional accessories:

Promotion!



Connection Cable A for U-WAVE

with Data Button for IP Caliper Type
Art No. 02AZD790A

Promo price: **76.00 €***

Suggested retail price: ~~110.00 €*~~



Digimatic Cable with Data Button IP Type

1 m, Caliper Type
Art No. 05CZA624

Suggested retail price: 100.00 €*



Digimatic Cable with Data Button IP Type

2 m, Caliper Type
Art No. 05CZA625

Suggested retail price: 107.00 €*

Promotion!



USB Input Tool Direct (Digimatic to USB)

2m Cable, Digimatic/Digimatic 2, with Data Button IP Caliper Type

Art No. 06AFM380A

Promo price: **111.00 €***

Suggested retail price: ~~141.00 €*~~

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 7.00 €*
