

Digital ABS AOS Caliper for Tolerance

Item number: 573-181-30

Images



Description

Caliper for tolerance measurement with depth gauge, for the series / input test


Features

Delivered:	In a box with SR44 battery
Range:	0 - 100 mm
Max. Permissible Error E MPE:	$\pm 0,02$ mm
Max. Permissible Error S MPE:	$\pm 0,04$ mm
Digital step:	0,01 mm
Max. response speed:	Unlimited
Measuring force:	7 - 14 N
Jaw retraction:	2 mm
ORIGIN (ABS-Zero):	Yes
ON/OFF:	Yes
ABS / INC (INC ZERO):	Yes
Low voltage alarm:	Yes
Data output:	Yes

Battery life: Approx. 18000 hours

Mass: 213 g

Dimensions

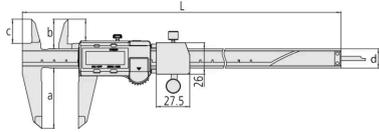

a: 40 mm

b: 21 mm

c: 16.5 mm

d: 16 mm

Accessories

Optional accessories:

Promotion!

Mitutoyo

MiCAT
the standard in world metrology software
MeasurLink

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)
Art No. 06AGR543

Promo price: 259.00 €*
Suggested retail price: ~~340.00 €*~~



USB-ITPAK

Standard accessories:



Depth Base Attachment for Caliper

75mm width for 100, 150, 200mm Range
Art No. 050083-10
Suggested retail price: 60.00 €*



Depth Base Attachment for Caliper

100mm width for 100, 150, 200mm Range
Art No. 050084-10
Suggested retail price: 67.00 €*

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 10.00 €*
