
 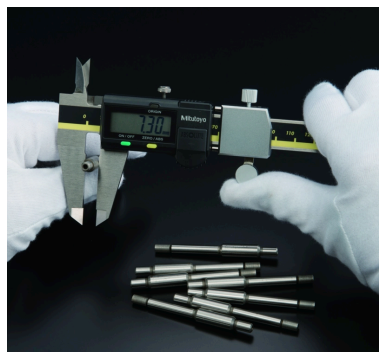


## Digital ABS AOS Caliper for Tolerance

Item number: 573-182-30

### Images



# ABSOLUTE®


### Description

Caliper for tolerance measurement with depth gauge, for the series / input test

### Features

<b>Delivered:</b>	In a box with SR44 battery
<b>Range:</b>	0 - 150 mm
<b>Max. Permissible Error E MPE:</b>	±0,02 mm
<b>Max. Permissible Error S MPE:</b>	±0,04 mm
<b>Digital step:</b>	0,01 mm
<b>Max. response speed:</b>	Unlimited
<b>Measuring force:</b>	7 - 14 N
<b>Jaw retraction:</b>	2 mm
<b>ORIGIN (ABS-Zero):</b>	Yes
<b>ON/OFF:</b>	Yes
<b>ABS / INC (INC ZERO):</b>	Yes
<b>Low voltage alarm:</b>	Yes
<b>Data output:</b>	Yes
<b>Battery life:</b>	Approx. 18000 hours
<b>Mass:</b>	233 g

### Dimensions

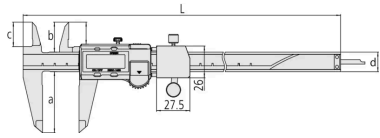

**a:** 50 mm

**b:** 24.5 mm

**c:** 20 mm

**d:** 16 mm

## Accessories

### Optional accessories:

**Promotion!**

**Mitutoyo**

**MiCAT**  
the standard in world  
metrology software  
**MeasurLink**

**USB-ITPAK Vers. 3.0**

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

**Promo price: 259.00 €\***

Suggested retail price: ~~340.00 €\*~~



### Standard accessories:

 


### Depth Base Attachment for Caliper

75mm width for 100, 150, 200mm Range

Art No. 050083-10

Suggested retail price: 60.00 €\*



### Depth Base Attachment for Caliper

100mm width for 100, 150, 200mm Range

Art No. 050084-10

Suggested retail price: 67.00 €\*

## Spare parts

### Consumable spares:



## Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 10.00 €\*  

---