


Digital ABS Inside Caliper

Item number: 573-645-20

Images

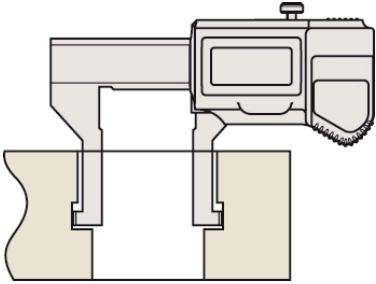

Dust- and
Water-
Protected

www.tuv.com
ID 0000045042

ABSOLUTE®

IP67

Description

Caliper with outside angled measuring tips

Features

Delivered:	In a box with SR44 battery
Range:	10.1 - 160 mm
Thumb roller:	Yes
Max. Permissible Error S MPE:	±0,05 mm
Max. response speed:	Unlimited
ORIGIN (ABS-Zero):	Yes
OFFSET:	10 mm
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Data output:	Yes
Battery life:	Approx. 5 years under normal use
Mass:	147 g

