

Digital ABS Inside Point Jaw Caliper

Item number: 573-646-20

Images



Dust- and
Water-
Protected

www.tuv.com
ID 0000045042

ABSOLUTE®

IP67

Description

Caliper with outside angled tips


Features

Delivered:	In a box with SR44 battery
Range:	20.1 - 170 mm
Thumb roller:	Yes
Max. Permissible Error S MPE:	±0,03 mm
Max. response speed:	Unlimited
ORIGIN (ABS-Zero):	Yes
OFFSET:	20 mm
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Data output:	Yes
Battery life:	Approx. 5 years under normal use

Mass:

157 g

Dimensions

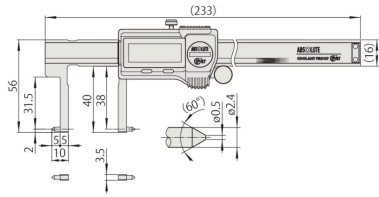

Accessories

Optional accessories:

Promotion!

Mitutoyo

MiCAT
the standard in world
metrology software
MeasurLink

USB-ITPAK

USB-ITPAK Vers. 3.0
USB Dongle + Manual (Software available
Online)
Art No. 06AGR543
Promo price: 259.00 €*
~~Suggested retail price: 340.00 €*~~

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882
Suggested retail price: 10.00 €*