

Digital ABS Neck Point Jaw Caliper

Item number: 573-652-20

Images



Dust- and Water-Protected

www.tuv.com
ID 0000045042

ABSOLUTE®

IP67


Description

Caliper with angled measuring tips

Features

Delivered:	In a box with SR44 battery
Range:	0 - 150 mm
Thumb roller:	Yes
Max. Permissible Error E MPE:	±0,03 mm
Max. response speed:	Unlimited
ORIGIN (ABS-Zero):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Data output:	Yes
Resolution:	0.01 mm
Mass:	157 g

Dimensions

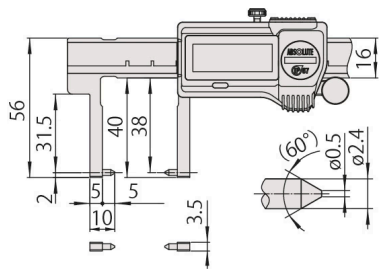

Accessories

Optional accessories:

Promotion!

Mitutoyo

MiCAT
the standard in world
metrology software
MeasurLink

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Promo price: 259.00 €*

Suggested retail price: ~~340.00 €*~~

USB-ITPAK

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 10.00 €*