

Digital ABS Scribing Caliper, Carb. Jaws

Item number: 573-677-20

Images



Dust- and
Water-
Protected

www.tuv.com
ID 0000045042

ABSOLUTE®

IP67


Description

Scribe caliper with carbide-tipped measuring surfaces and depth gauge

Features

Battery life:	approx. 5 years
Delivered:	In a box with SR44 battery
Range:	0 - 200 mm
Max. Permissible Error E MPE:	±0,02 mm
Max. Permissible Error S MPE:	±0,04 mm
Digital step:	0,01 mm
Max. response speed:	Unlimited
ORIGIN (ABS-Zero):	Yes
Auto Power OFF after 20 min. non use:	Yes
Low voltage alarm:	Yes
Data output:	Yes
Mass:	196 g

Dimensions

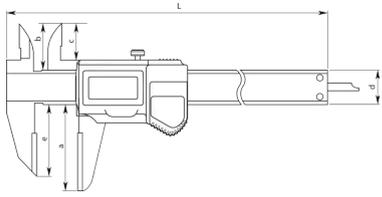

a: 50 mm

b: 25 mm

c: 20.5 mm

d: 16 mm

e: 43 mm

Accessories

Optional accessories:

Promotion!

Mitutoyo

MiCAT

the standard in world metrology software

measurLink

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available Online)

Art No. 06AGR543

Promo price: 259.00 €*
Suggested retail price: 340.00 €*



 
USB-ITPAK

Standard accessories:



Depth Base Attachment for Caliper

75mm width for 100, 150, 200mm Range
Art No. 050083-10
Suggested retail price: 60.00 €*



Depth Base Attachment for Caliper

100mm width for 100, 150, 200mm Range
Art No. 050084-10
Suggested retail price: 67.00 €*

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 10.00 €*
