


Digital ABS Back-Jaw Caliper, IP67

Item number: 573-719-20

Images

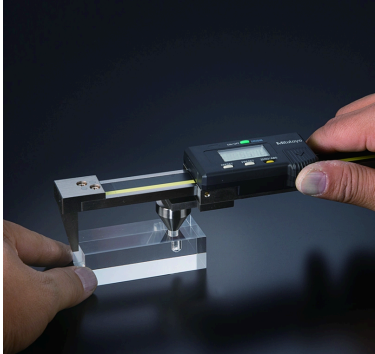

Description


The ABSOLUTE Digimatic back-jaw centreline calipers offer you the following benefits:

- Specially designed to allow you to measure hole centre-to-centre or edge-to-centre distances.
- You can read measurements more easily from above, thanks to the jaws being on the back of the slide.
- Direct reading of pitch measurements is also available due to the offset value setting function.

Features

Model:	NTD10B-P30M
Delivered:	In a box with SR44 battery
Range:	10.1 - 300 mm
Max. Permissible Error S MPE:	±0,15 mm
Digital step:	0,01 mm
Max. response speed:	Unlimited
ORIGIN (ABS-Zero):	Yes
OFFSET:	10 mm
ABS / INC (INC ZERO):	Yes
Low voltage alarm:	Yes
Data output:	Yes
Battery life:	Approx. 5 years under normal use
Mass:	555 g

Dimensions

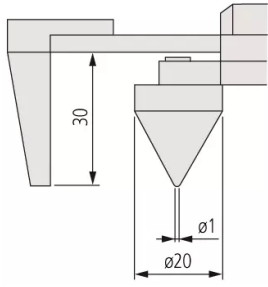

Accessories

Optional accessories:

Promotion!

Mitutoyo

MiCAT

the standard in world
metrology software
MeesurLink

USB-ITPAK Vers. 3.0

USB Dongle + Manual (Software available
Online)

Art No. 06AGR543

Promo price: **259.00 €***

Suggested retail price: ~~340.00 €*~~

USB-ITPAK

Spare parts

Consumable spares:



Battery SR44 1,5 V

Art No. 938882

Suggested retail price: 10.00 €*